

MPL POWER SUPPLY 3-PHASE, SMOOTHED

IN: 208-520VAC+/- 5% OUT: 24V/50ADC



Current: 50 A

Output rating: 1200 W

Any mounting position on vertical wall, condensation not permissible

Ürün Linki

örnekleme

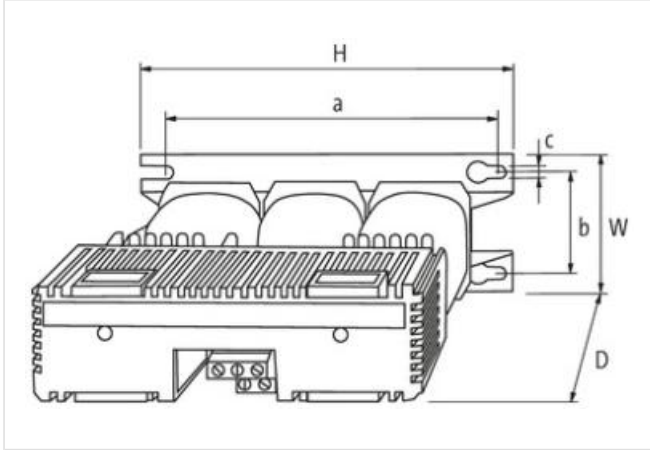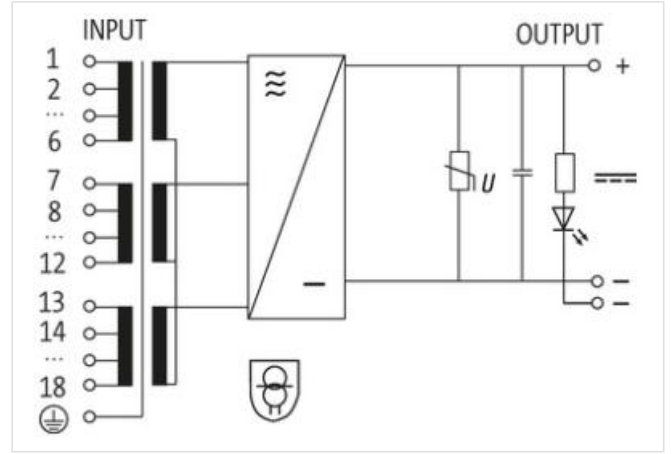

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27049002
ECLASS-7.0	27049002
ECLASS-8.0	27049002
ECLASS-9.0	27040701
ETIM-5.0	EC002540
GTIN	4048879079082
Gümrük tarife no (gtip)	85044095
Paket miktarı	1

Electrical data

Security level	SELV
----------------	------

Electrical data | Supply

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.

Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalı sınırlıdır. Sürüm: 2024-05-22

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Power frequency 50 ... 60 Hz

Electrical data | Input

Input voltage AC min.	208 V
Input voltage AC max.	520 V
Phase number input	3
Efficiency	77 %

Electrical data | Output

Fuse protection secondary side external	50 A
Output suppression	LED, Screening capacitor, VDR
Output voltage DC	24 V
Output voltage adjustable	no
Output current max.	50 A
Characteristic secondary fuse	Inertia
Ripple max.	2 %

Mechanical data | Mounting data

Suitable for mounting type	Schlüssellochauhängung
Mounting dimension a	256,5 mm
Mounting dimension b	105 mm
Mounting dimension c	7,5 mm
Height	280 mm
Width	131 mm
Depth	310 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	55 °C

Conformity

Product standard	EN 61558-2-6, EN 62041 category I
EMC	EN 55011 B, EN 61000-3-2