



MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 500VA IN: 240-415VAC OUT: 110-110-20VAC

Single-phase - Control and Isolation Transformers
500 VA
Isolation class T 60/B

Ürün Linki

örnekleme

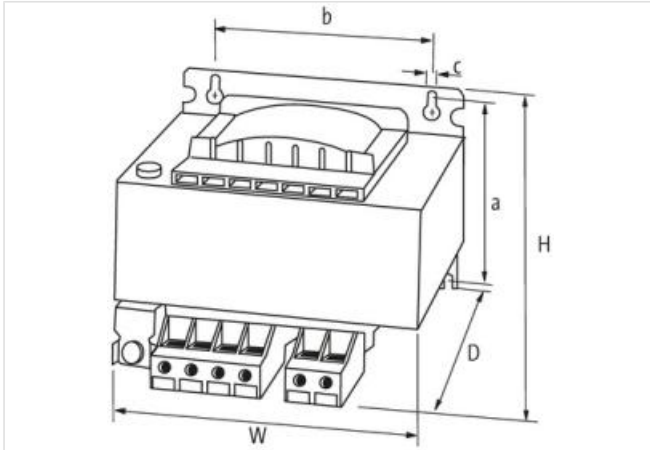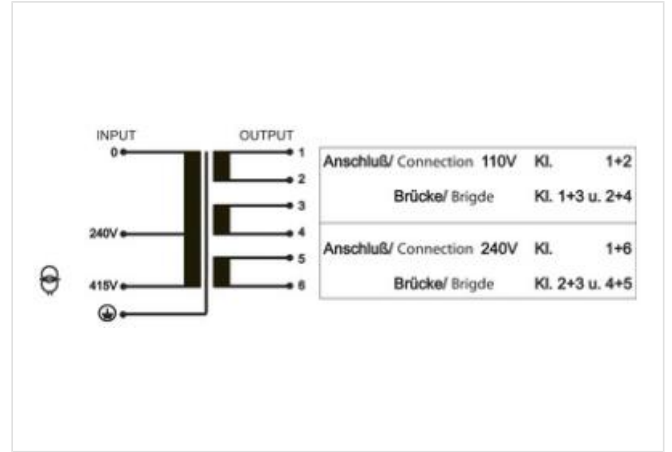

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
GTIN	4048879079013
Gümrük tarife no (gtip)	85043180
Paket miktarı	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage 1 AC	240 V
Input voltage 2 AC	415 V
Input current at input voltage 1 AC	2,3 A
Input current at input voltage 2 AC	1,36 A
Inrush current at input voltage 1	58,3 A
Inrush current at input voltage 2	33,6 A
Short-circuit current at input voltage 1	51,33 A
Short-circuit current at input voltage 2	29,7 A

Electrical data | Output

Output voltage AC 1	110 V
Output voltage AC 2	240 V
Output voltage adjustable	yes
Power rating AC max.	500 VA

Device protection | Electrical

Insulation test voltage input - output	4 kV
--	------

Mechanical data | Mounting data

Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	91 mm
Mounting dimension b	122 mm
Mounting dimension c	7 mm
Height	112,6 mm
Width	150 mm
Depth	170 mm
Diameter bore	7 mm
Length bore	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0
------------------	---