



MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 1000VA IN: 240-415VAC OUT: 110-110-20VAC

Single-phase - Control and Isolation Transformers
1000 VA
Isolation class T 60/B

Ürün Linki

örnekleme

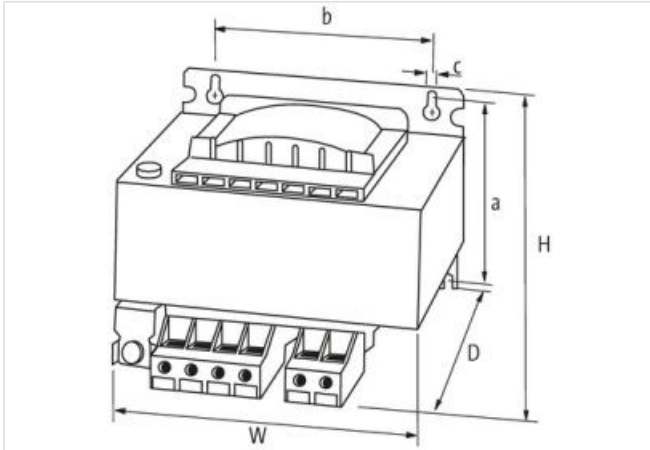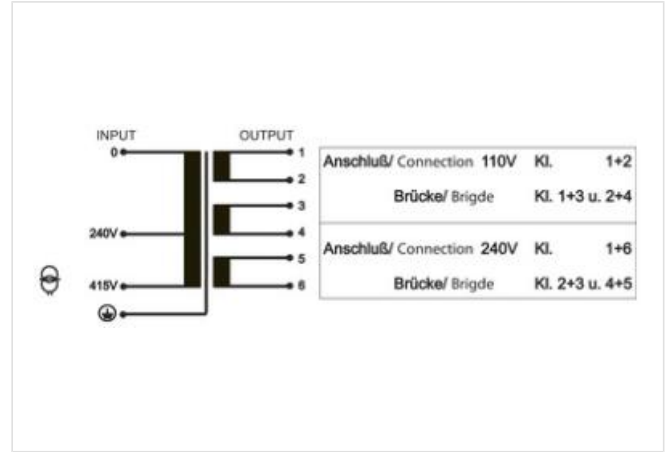

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
GTIN	4048879078863
Gümrük tarife no (gtip)	85043180
Paket miktarı	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage 1 AC	240 V
Input voltage 2 AC	415 V
Input current at input voltage 1 AC	4,64 A
Input current at input voltage 2 AC	2,68 A
Inrush current at input voltage 1	110 A
Inrush current at input voltage 2	62,5 A
Short-circuit current at input voltage 1	138 A
Short-circuit current at input voltage 2	79,4 A
Electrical data Output	
Output voltage AC 1	110 V
Output voltage AC 2	240 V
Output voltage adjustable	yes
Power rating AC max.	1000 VA
Device protection Electrical	
Insulation test voltage input - output	4 kV
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	111,5 mm
Mounting dimension b	135 mm
Mounting dimension c	7 mm
Height	138 mm
Width	174 mm
Depth	160 mm
Diameter bore	7 mm
Length bore	11 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0