



## MTS 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 40VA IN: 208...550VAC OUT: 2x115VAC

Single-phase - Control and Isolation Transformers  
40 VA  
Isolation class T 40/B  
Other voltages on request.

### Ürün Linki

örnekleme

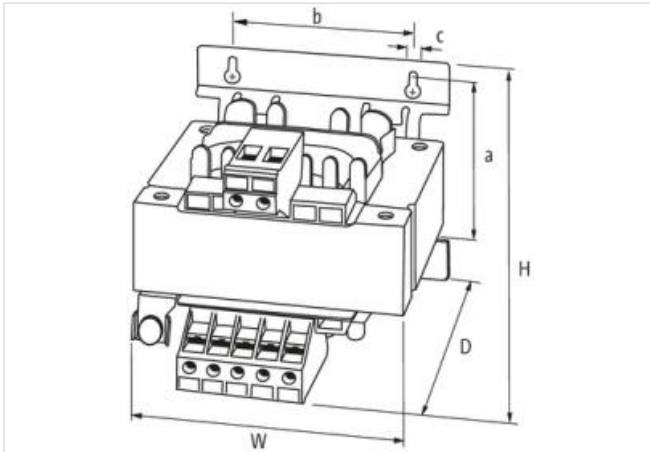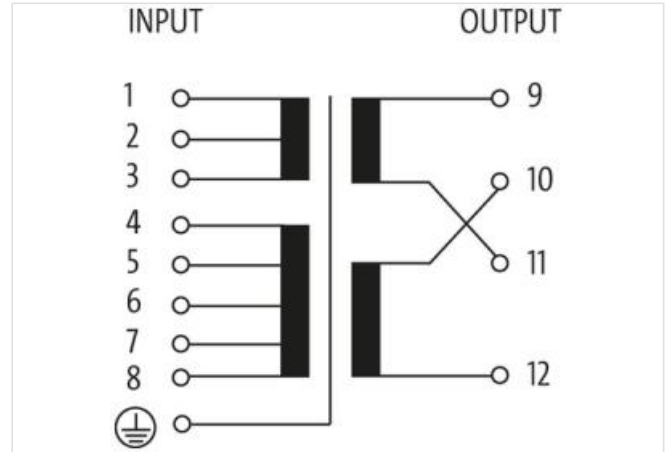

Ürün Image farklı olabilir



### Ticari bilgiler

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27031302 |
| ECLASS-6.1  | 27031302 |
| ECLASS-7.0  | 27031302 |
| ECLASS-8.0  | 27031302 |
| ECLASS-9.0  | 27031302 |
| ECLASS-10.1 | 27031302 |

|                                                 |                                                       |
|-------------------------------------------------|-------------------------------------------------------|
| ECLASS-11.1                                     | 27031302                                              |
| ECLASS-12.0                                     | 27031302                                              |
| ETIM-5.0                                        | EC002486                                              |
| GTIN                                            | 4048879444187                                         |
| Gümrük tarife no (gtip)                         | 85043180                                              |
| Paket miktarı                                   | 1                                                     |
| <b>Electrical data   Supply</b>                 |                                                       |
| Power frequency                                 | 50 ... 60 Hz                                          |
| <b>Electrical data   Input</b>                  |                                                       |
| Input voltage 1 AC                              | 208 V                                                 |
| Input voltage 2 AC                              | 550 V                                                 |
| Input voltage AC                                | 208, 230, 380, 400, 420, 440, 460, 480, 500, 525, 550 |
| Input current at input voltage 1 AC             | 0,25 A                                                |
| Input current at input voltage 2 AC             | 0,095 A                                               |
| Inrush current at input voltage 1               | 3,2 A                                                 |
| Inrush current at input voltage 2               | 1,2 A                                                 |
| Short-circuit current at input voltage 1        | 1,9 A                                                 |
| Short-circuit current at input voltage 2        | 0,7 A                                                 |
| <b>Electrical data   Output</b>                 |                                                       |
| Output voltage                                  | 1 × 230 / 1 × 115 / 2 × 115 V AC                      |
| Output voltage AC 1                             | 230 V                                                 |
| Output voltage AC 2                             | 115 V                                                 |
| Output voltage adjustable                       | yes                                                   |
| Power rating AC max.                            | 40 VA                                                 |
| <b>Device protection   Electrical</b>           |                                                       |
| Insulation test voltage input - output          | 4 kV                                                  |
| <b>Mechanical data   Mounting data</b>          |                                                       |
| Mounting method                                 | geschnappt                                            |
| Suitable for mounting type                      | Mounting rail TH35, Long-hole mounting, (EN 60715)    |
| Mounting dimension a                            | 56 mm                                                 |
| Mounting dimension b                            | 56 mm                                                 |
| Height                                          | 88 mm                                                 |
| Width                                           | 78 mm                                                 |
| Depth                                           | 93 mm                                                 |
| Diameter bore                                   | 4,8 mm                                                |
| Length bore                                     | 8,4 mm                                                |
| <b>Environmental characteristics   Climatic</b> |                                                       |
| Operating temperature min.                      | -20 °C                                                |
| Operating temperature max.                      | 40 °C                                                 |
| Storage temperature min.                        | -20 °C                                                |
| Storage temperature max.                        | 80 °C                                                 |
| <b>Conformity</b>                               |                                                       |
| Product standard                                | EN 61558-1, EN 61558-2-4, EN 62041 category 0         |
| <b>Connection type 3</b>                        |                                                       |
| Connection type 1                               | Input                                                 |
| Connection type 2                               | Output                                                |
| Connection                                      | Screw terminals SK                                    |
| Family construction form                        | terminal                                              |
| Gender                                          | female                                                |
| No. of poles                                    | 8                                                     |
| PIN 1                                           | 1                                                     |

|                          |                    |
|--------------------------|--------------------|
| PIN 2                    | 2                  |
| PIN 3                    | 3                  |
| PIN 4                    | 4                  |
| PIN 5                    | 5                  |
| PIN 6                    | 6                  |
| PIN 7                    | 7                  |
| PIN 8                    | 8                  |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| No. of poles             | 4                  |
| PIN 1                    | 9                  |
| PIN 2                    | 10                 |
| PIN 3                    | 11                 |
| PIN 4                    | 12                 |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | metallic           |
| No. of poles             | 1                  |
| PIN 1                    | PE                 |