



## MTS 1-PHASE SAFETY TRANSFORMER

P: 40VA IN: 230/400VAC +/- 15VAC OUT: 24VAC

Single-phase safety transformer  
40 VA  
Isolation class T 40/B  
Other voltages on request.

### Ürün Linki

örnekleme

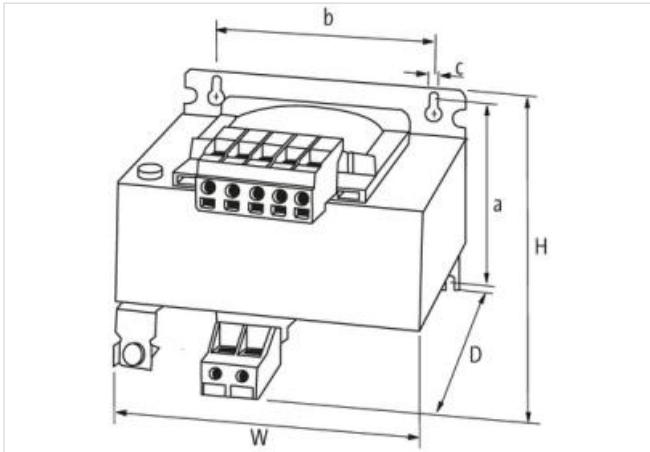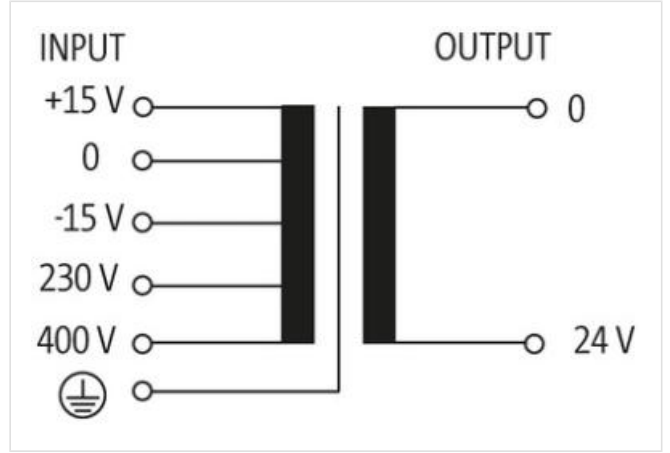

Ürün Image farklı olabilir



### Ticari bilgiler

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27031302 |
| ECLASS-6.1  | 27031302 |
| ECLASS-7.0  | 27031302 |
| ECLASS-8.0  | 27031302 |
| ECLASS-9.0  | 27031302 |
| ECLASS-10.1 | 27031302 |

|                                                 |                                                    |
|-------------------------------------------------|----------------------------------------------------|
| ECLASS-11.1                                     | 27031302                                           |
| ECLASS-12.0                                     | 27031302                                           |
| ETIM-5.0                                        | EC002486                                           |
| GTIN                                            | 4048879078450                                      |
| Gümrük tarife no (gtip)                         | 85043180                                           |
| Paket miktarı                                   | 1                                                  |
| <b>Electrical data</b>                          |                                                    |
| Security level                                  | SELV                                               |
| <b>Electrical data   Supply</b>                 |                                                    |
| Power frequency                                 | 50 ... 60 Hz                                       |
| <b>Electrical data   Input</b>                  |                                                    |
| Input voltage 1 AC                              | 230 V                                              |
| Input voltage 1 AC min.                         | 195,5 V                                            |
| Input voltage 1 AC max.                         | 264,5 V                                            |
| Input voltage 2 AC                              | 400 V                                              |
| Input voltage 2 AC min.                         | 340 V                                              |
| Input voltage 2 AC max.                         | 460 V                                              |
| Input current at input voltage 1 AC             | 0,24 A                                             |
| Input current at input voltage 2 AC             | 0,138 A                                            |
| Inrush current at input voltage 1               | 1,35 A                                             |
| Inrush current at input voltage 2               | 0,78 A                                             |
| Short-circuit current at input voltage 1        | 1,75 A                                             |
| Short-circuit current at input voltage 2        | 1 A                                                |
| <b>Electrical data   Output</b>                 |                                                    |
| Output voltage AC                               | 24 V                                               |
| Output voltage adjustable                       | no                                                 |
| Power rating AC max.                            | 40 VA                                              |
| <b>Device protection   Electrical</b>           |                                                    |
| Insulation test voltage input - output          | 4 kV                                               |
| <b>Mechanical data   Mounting data</b>          |                                                    |
| Mounting method                                 | geschnappt                                         |
| Suitable for mounting type                      | Mounting rail TH35, Long-hole mounting, (EN 60715) |
| Mounting dimension a                            | 56 mm                                              |
| Mounting dimension b                            | 56 mm                                              |
| Mounting dimension c                            | 4,8 mm                                             |
| Height                                          | 78 mm                                              |
| Width                                           | 78 mm                                              |
| Depth                                           | 93 mm                                              |
| Diameter bore                                   | 4,8 mm                                             |
| Length bore                                     | 8,4 mm                                             |
| <b>Environmental characteristics   Climatic</b> |                                                    |
| Operating temperature min.                      | -20 °C                                             |
| Operating temperature max.                      | 40 °C                                              |
| Storage temperature min.                        | -40 °C                                             |
| Storage temperature max.                        | 80 °C                                              |
| <b>Conformity</b>                               |                                                    |
| Product standard                                | EN 61558-2-4, EN 61558-2-6, EN 62041 category 0    |
| <b>Connection type 3</b>                        |                                                    |
| Connection type 1                               | Input                                              |
| Connection type 2                               | Output                                             |
| Connection                                      | Screw terminals SK                                 |

|                          |                    |
|--------------------------|--------------------|
| Family construction form | terminal           |
| Gender                   | female             |
| No. of poles             | 5                  |
| PIN 1                    | + 15 V             |
| PIN 3                    | - 15 V             |
| PIN 4                    | 230 V              |
| PIN 5                    | 400 V              |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| No. of poles             | 2                  |
| PIN 2                    | 24 V DC            |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | metallic           |
| No. of poles             | 1                  |
| PIN 1                    | PE                 |