

MOTOR SUPPRESSION SHIELDING PLUGGABLE

5M PUR 5,5KW-3X575

3× 575 V AC




VDR/star

5.0 m

PUR cable black, 4× 1.5 mm², numbered wires, DESINA conform

Ürün Linki

örnekleme

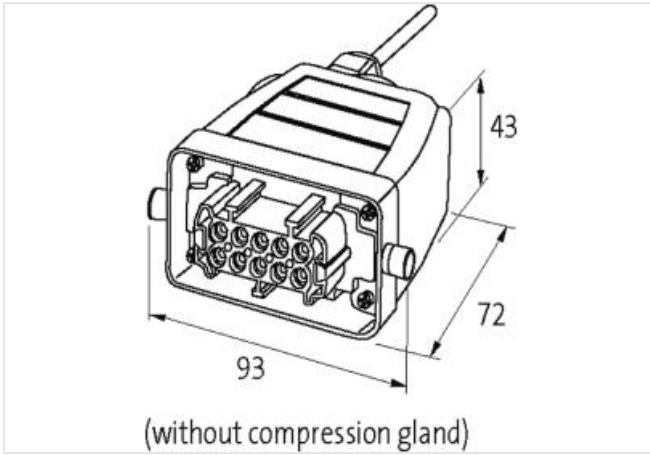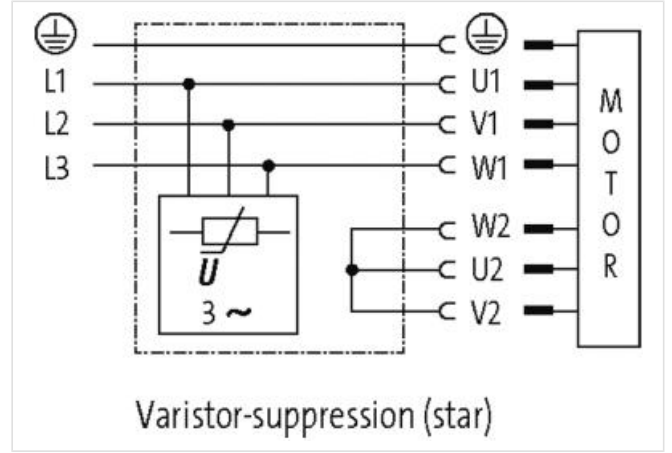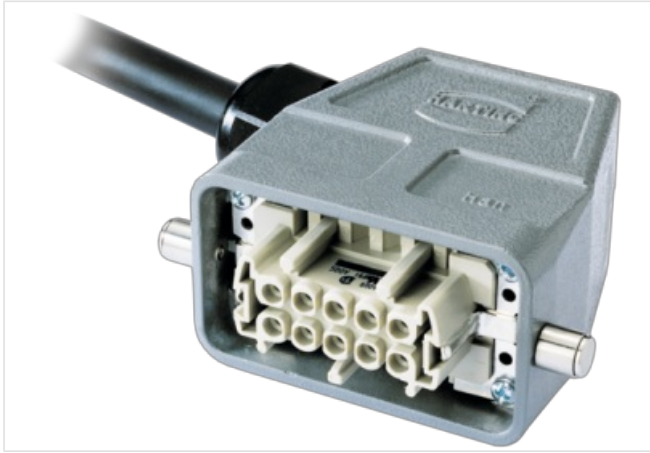

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879015134
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Electrical data Supply	
Power frequency	10 ... 400 Hz
Electrical data Input	
Input voltage AC min.	400 V
Input voltage AC max.	575 V
Installation Connection	
Gender	female
Installation Pin assignment	
No. of poles	10 + PE
Mechanical data Material data	
Coating housing	powder-coated
Material housing	Aluminum die casting
Mechanical data Mounting data	
Height	43 mm
Width	93 mm
Depth	72 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C