

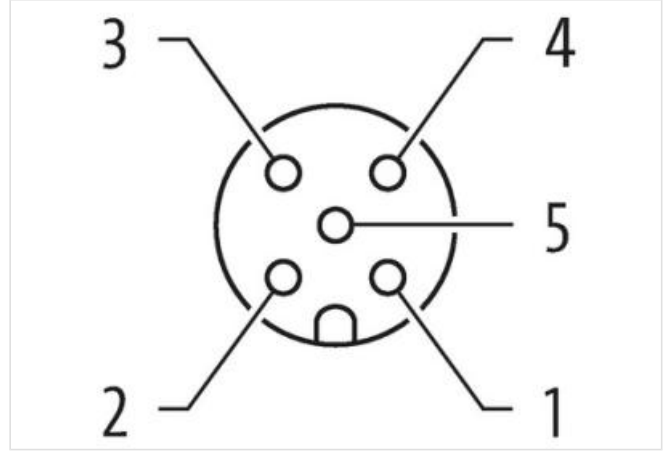
M12-DISTRIBUTOR BOX 4-WAY, 5-POLE WITHOUT LED

MVC4-UQQ5.0-XA 5m PUR-CNOMO-cable 8x0,34/3x1

4-way, 5-pole
PUR/PVC (CNOMO)
5.0 m
without LED

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ETIM-5.0	EC002585
GTIN	4048879000178
Gümrük tarife no (gtip)	85444290
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current max.	10 A

Industrial communication

Number of signals per port	2
----------------------------	---

Installation | Connection

Mounting set	M12 x 1
--------------	---------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed

Mechanical data | Mounting data

Mounting method	Schraubgewinde
Height	117 mm
Width	54 mm

Depth 33 mm

Environmental characteristics | Climatic

Operating temperature min. -20 °C
Operating temperature max. 80 °C

Connection type 2

Family construction form free cable end
No. of poles 11
Family construction form M12
Gender female
Color contact carrier black
Coding A
No. of poles 5
PIN 1 +
PIN 3 -
PIN 5 PE