

Injection Box

MVP12V-FN9F-GH

M12 plug connection



Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

10-way

Ürün Linki

örnekleme

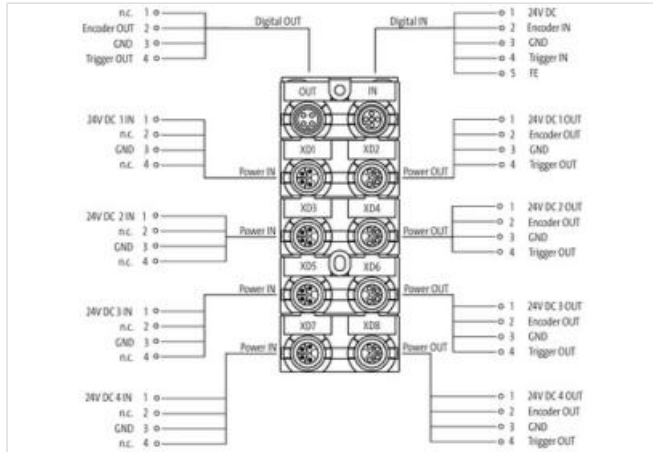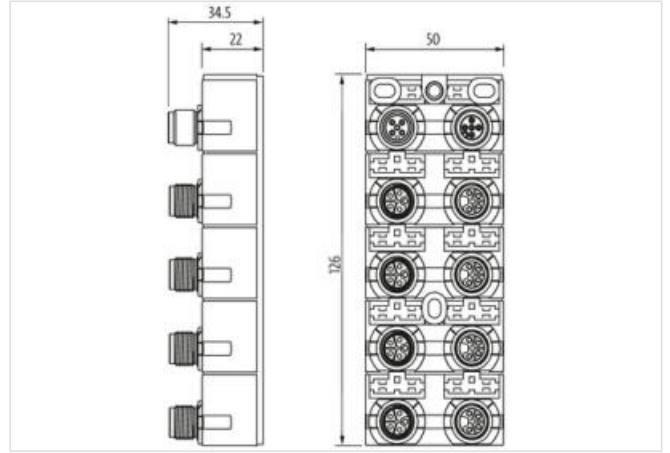

Ürün Image farklı olabilir



Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	18 V
Operating voltage DC max.	28 V

Electrical data | Output

Output current	16000 mA
----------------	----------

Device protection | Electrical

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.

Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalı sınırlıdır. Sürüm: 2024-05-04

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Installation height max. ASL	2000 m
Degree of protection (EN IEC 60529)	IP65, IP67
Invers-polarity protection	yes
Short-circuit protected	yes
Material group (IEC 60664-1)	III
Device protection Mechanical	
Shock resistance (EN IEC 60068-2-27)	50 g, 11 ms
Vibration resistance (EN IEC 60068-2-6)	0,75 mm (10 ... 70 Hz), 15 g (70 ... 500 Hz)
Mechanical data Mounting data	
Net weight	254 g
Installation measurement	75 mm
Height	34,5 mm
Width	50 mm
Length	126 mm
Environmental characteristics Electromagnetic compatibility	
Interference emission	IEC 61000-6-4
Immunity to interference	IEC 61000-6-2
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	45 °C
Storage temperature min.	-25 °C
Storage temperature max.	70 °C
Conformity	
CE	2014/30/EU & 2011/65/EU
UKCA	EN IEC 61000-6-2: 2019 Electromagnetic compatibility (EMC) – Part 6-2: Generic standards – Immunity standard for industrial environments (IEC 61000-6-2:2016 EN 61000-6-3: 2007 + A1:2011 Electromagnetic compatibility (EMC) - Part 6-3: Generic standards - E
Approvals	
UL	UL2367 - Zusatz für Mico Port
Connection type 4	
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	4
PIN 1	n.c.
PIN 2	Encoder Out
PIN 3	0 V
PIN 4	Trigger Out
PIN 5	n.c.
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	24 V DC 1 Out
PIN 2	Encoder In
PIN 3	0 V
PIN 4	Trigger In
PIN 5	n.c.
Family construction form	M12

Gender	female
Color contact carrier	black
Coding	L
No. of poles	4
PIN 1	24 V DC 1 2 3 4 Out
PIN 2	Encoder Out
PIN 3	0 V
PIN 4	Trigger Out
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	L
No. of poles	4
PIN 1	24 V DC 1 2 3 4 In
PIN 2	n.c.
PIN 3	0 V
PIN 4	n.c.
Ticari bilgiler	
GTIN	4048879887373
Gümrük tarife no (gtip)	85389099
Paket miktarı	1