
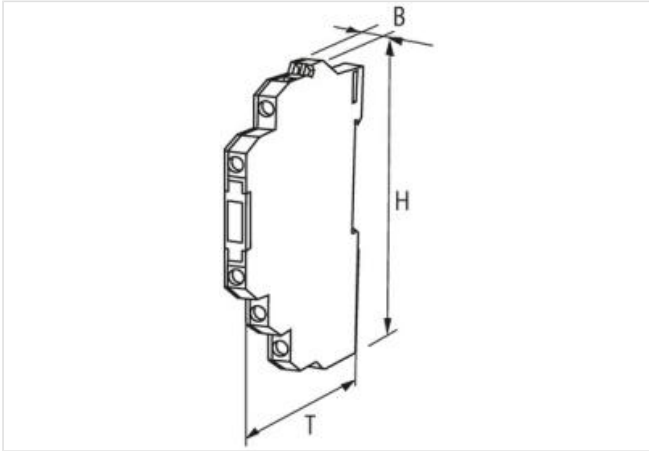


MIRO 6,2 Valvecontrol 24VDC/1ms

In:24VDC OUT:24VDC/1,5A

Switching accelerator: 1 ms/24 V DC
Screw terminals**Ürün Linki**

örnekleme

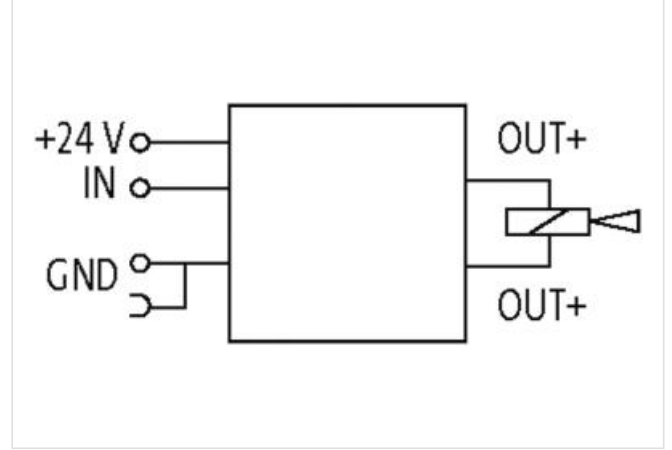

Ürün Image farklı olabilir

**Electrical data | Input**

Input voltage DC	24 V
Input voltage DC min.	18 V
Input voltage DC max.	30 V
Input current	13 mA

Electrical data | Output

Output current	1,5 A
Output current max.	0,38 A

Duration surge current max.	1 ms
Switching frequency max.	20 Hz
Surge current max.	1,5 A

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	91 mm
Width	6,2 mm
Depth	71 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-25 °C
Storage temperature max.	50 °C

Connection type 4

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	GD
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	In
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	O 1
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	O 2

Ticari bilgiler

GTIN	4048879571876
Gümrük tarife no (gtip)	85437090
Paket miktarı	10