

TRANSFER PLUG , PASSIV

UFL 40-pole

Ribbon cable connector

40-pole



Spring clamp terminals

Via the combined fixing mechanism, connectors with or without strain relief can be connected.

for plugs with or without strain relief (DIN 41651); for plugs with strain relief, it may be necessary to remove the bottom hook

Ürün Linki

örnekleme

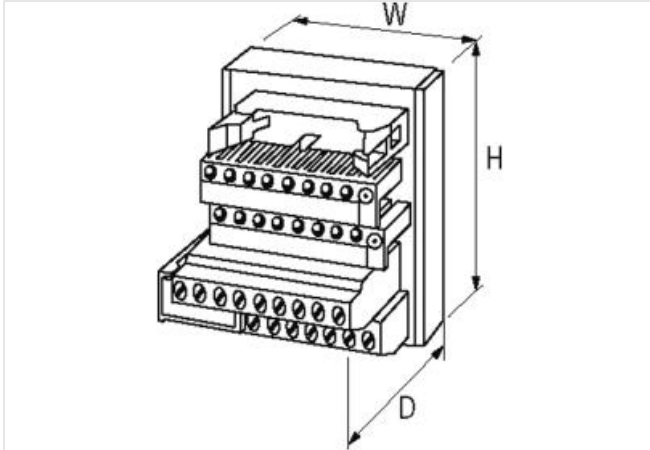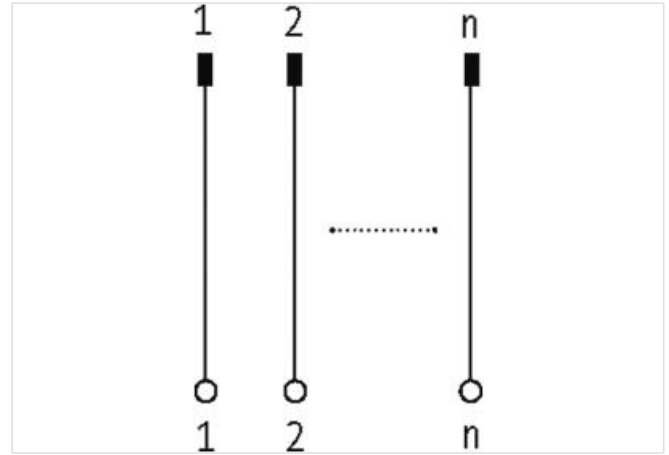

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27260710
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.

Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalı sınırlıdır. Sürüm: 2024-05-21

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

GTIN	4048879023887
------	---------------

Gümrük tarife no (gtip)	85366990
-------------------------	----------

Paket miktarı	10
---------------	----

Electrical data | Supply

Operating voltage DC	24 V
----------------------	------

Operating current max.	1 A
------------------------	-----

Installation | Connection

Connection	Spring clamp terminals FK
------------	---------------------------

Device protection | Electrical

Pollution Degree	2
------------------	---

Overvoltage category (EN 60664-1)	III
-----------------------------------	-----

Mechanical data | Mounting data

Mounting method	geschnappt
-----------------	------------

Suitable for mounting type	mounting rail, (EN 60715)
----------------------------	---------------------------

Height	75 mm
--------	-------

Width	70 mm
-------	-------

Depth	70 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	70 °C
----------------------------	-------