
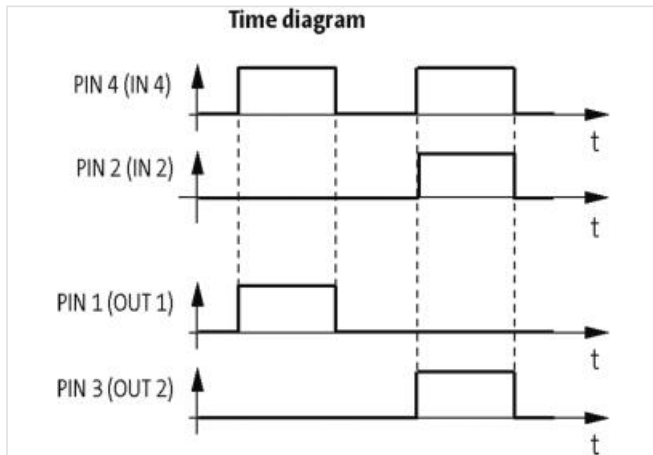


DC MOTOR CONTROL 24V/1A 2X M12

DC Motor control
24 V DC
Current: 1 A

Ürün Linki

örnekleme

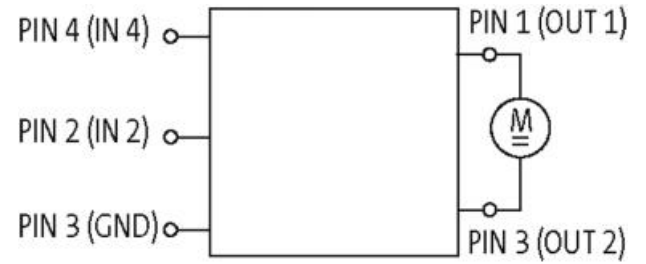

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27242609
ECLASS-6.1	27242609
ECLASS-7.0	27242609
ECLASS-8.0	27242609
ECLASS-9.0	27242609
ECLASS-10.1	27242609
ECLASS-11.1	27242609
ECLASS-12.0	27242609

ETIM-5.0	EC002615
GTIN	4048879315111
Gümrük tarife no (gtip)	85365080
Paket miktarı	1
Electrical data Input	
Input voltage DC	24 V
Input voltage DC min.	5 V
Input voltage DC max.	32 V
Input current	1000 mA
Electrical data Output	
Output voltage adjustable	no
Output current max.	1 A
Installation Connection	
Family construction form	M12
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, screwed
Protective circuit output	yes, yes, Suppressor diode, 1,5 kW / 36 V
Over voltage protection	yes
Mechanical data Mounting data	
Height	24,5 mm
Width	24,5 mm
Depth	60,5 mm
Environmental characteristics Climatic	
Operating temperature min.	0 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C