



MET SINGLE-PHASE SAFETY TRANSFORMER

P:100VA IN:110VAC OUT:24VAC with fuse-clamp

Single-phase - Control and Isolation Transformers
100 VA
Isolation class T 60/B
with fuse

Ürün Linki

örnekleme

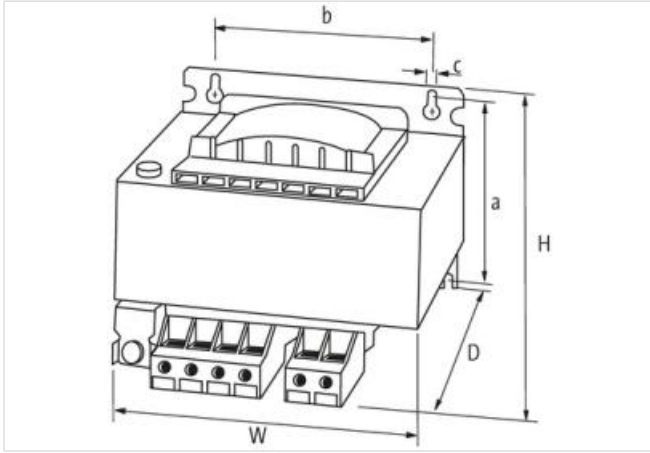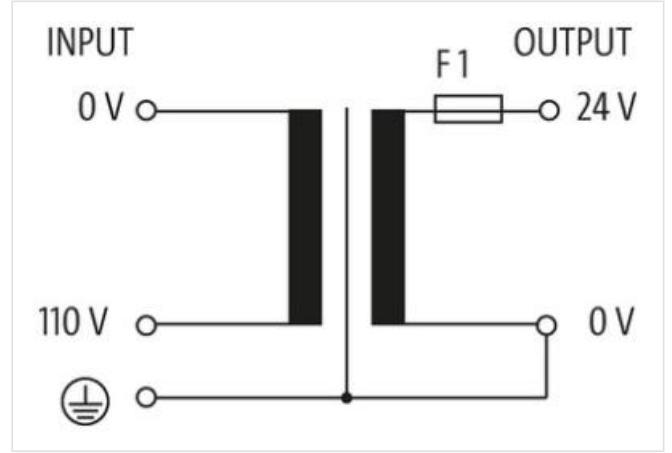

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27031202
ECLASS-7.0	27031202
ECLASS-8.0	27031202
ECLASS-9.0	27031202
ETIM-5.0	EC002485
GTIN	4048879073776
Gümrük tarife no (gtip)	85043180
Paket miktarı	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage 1 AC	110 V
Input voltage AC	110 V
Current input AC	1,07 A
Max. inrush current	9 A
Short-circuit current	12 A

Electrical data | Output

Output voltage AC	24 V
Output voltage adjustable	no
Power rating AC max.	100 VA

Device protection | Electrical

Insulation test voltage input - output	3,5 kV
--	--------

Mechanical data | Mounting data

Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	47 mm
Mounting dimension b	64 mm
Mounting dimension c	4,8 mm
Height	82 mm
Width	6 mm
Depth	105 mm
Diameter bore	4,8 mm
Length bore	8 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-2-4, EN 61558-2-6, EN 62041 category 0
------------------	---