

VALVE PLUG SUPPRESSOR FORM BI - 11MM

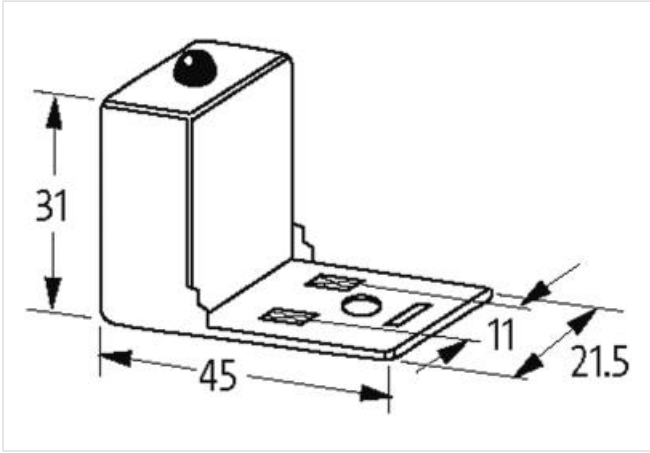
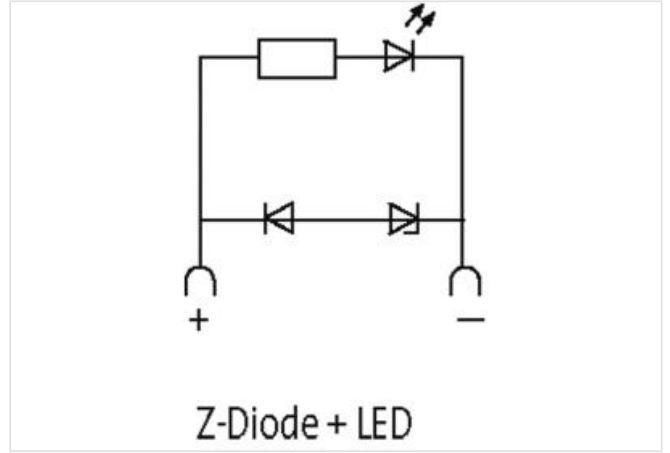
Zener diode and LED, 24VDC/100VA/W

24 V AC/DC

Z-Diode + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

Note PIN arrangement (PE at cable outlet of connector). 180° turned version on request.

Ürün Linki
örnekleme


Ürün Image farklı olabilir


Ticari bilgiler

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879011938
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Electrical data	
Drop-out delay time max.	20 ms
Holding power max.	100 W
Electrical data Supply	
Cut-off peak voltage max.	55 V
Electrical data Input	
Input voltage AC min.	18 V
Input voltage AC max.	30 V
Input voltage DC min.	18 V
Input voltage DC max.	30 V
Diagnostics	
Status indication LED	yellow
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Coating contact	silver-plated
Color housing	black
Material housing	PA
Material contact	Bronze
Mechanical data Mounting data	
Height	31 mm
Width	45 mm
Depth	21,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C