

EMC-SUPPRESSORS FOR VALVE PLUG

Diode and LED, 24VDC/60VA/W



24 V AC/DC

Diode + LED (green)

Remove plug gasket when fitting adapter. Other LED colors on request.

Ürün Linki

örnekleme

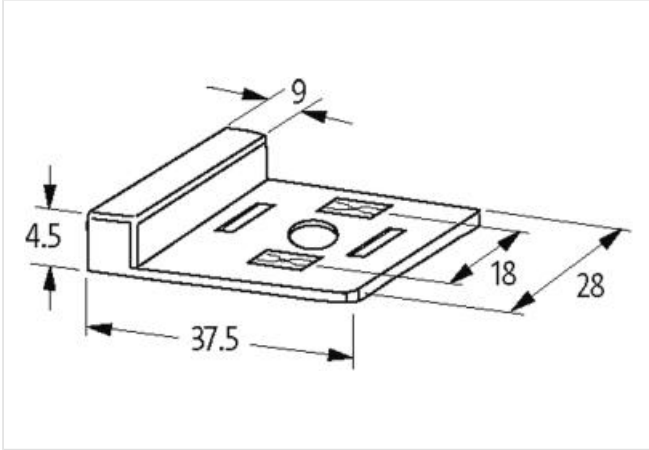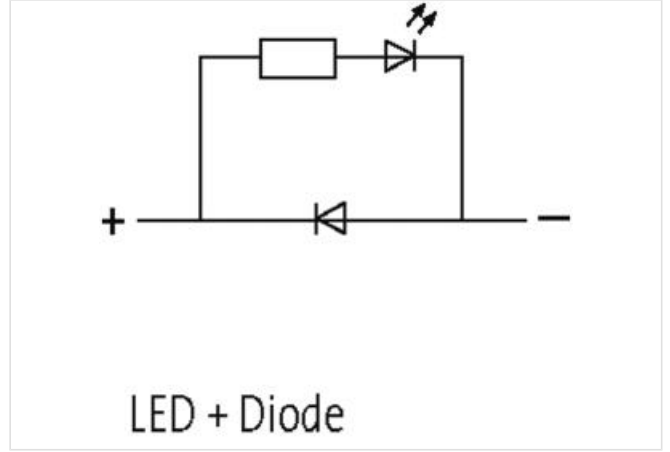

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879011310
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Electrical data	
Capacity CX	200 ms
Holding power max.	60 W
Electrical data Supply	
Cut-off peak voltage max.	1 V
Electrical data Input	
Input voltage AC min.	20 V
Input voltage AC max.	27 V
Input voltage DC min.	20 V
Input voltage DC max.	27 V
Diagnostics	
Status indication LED	yellow
Installation	
Type of contact	A
Contact distance	18 mm
Mechanical data Material data	
Coating contact	silver-plated
Material housing	PUR
Material contact	Bronze
Mechanical data Mounting data	
Height	4,5 mm
Width	37,5 mm
Depth	28 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C