

CAP BIG WITH PLUG.SPRING-TERM 21-POLE

For use with 4-,6-,8-way d-box M12 5--pole

Cap for 4-, 6-, and 8-way distribution box, 5-pole



Spring clamp plug-in terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Ürün Linki

örnekleme

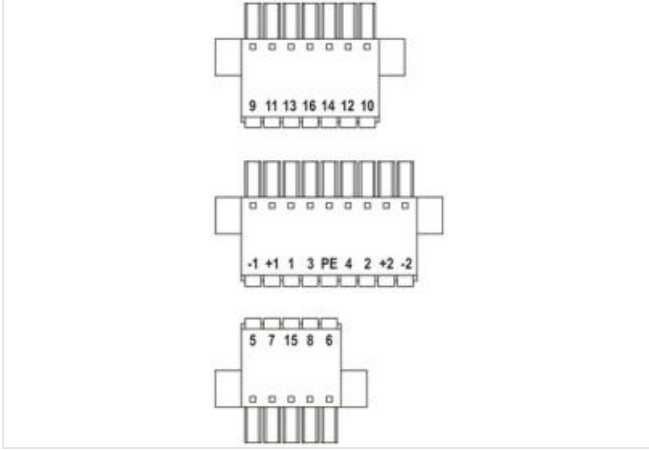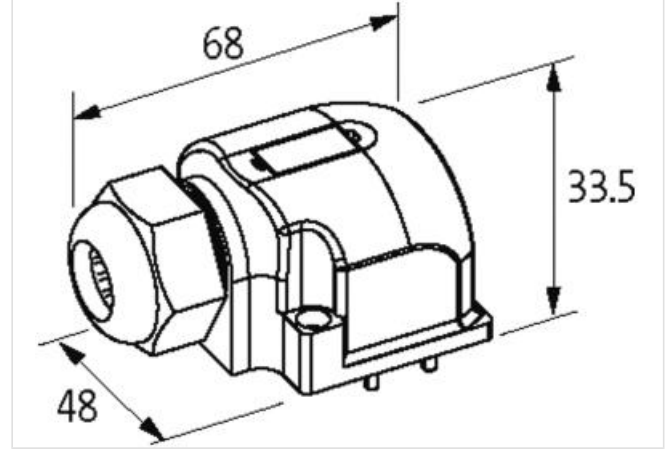

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
GTIN	4048879058018
Gümrük tarife no (gtip)	85369010

Paket miktarı 1

Electrical data | Supply

Total current max. 8 A

Installation

Connection cross section max. 1,5 mm²

AWG number max. 16

Installation | Connection

Connection Spring clamp terminals FK

Mechanical data | Mounting data

Height 33,5 mm

Width 48 mm

Depth 68 mm

Connection type 1

Family construction form Cap

No. of poles 21