



## DC-MOTOR COMMUTATING CIRCUIT

IN: 24 VDC - OUT: 24 VDC / 3 A

Transistor 3 A  
24 V DC  
Spring clamp terminals  
Start-stop/left-right (active stop mode)  
Over current / temperature monitoring

### Ürün Linki

örnekleme

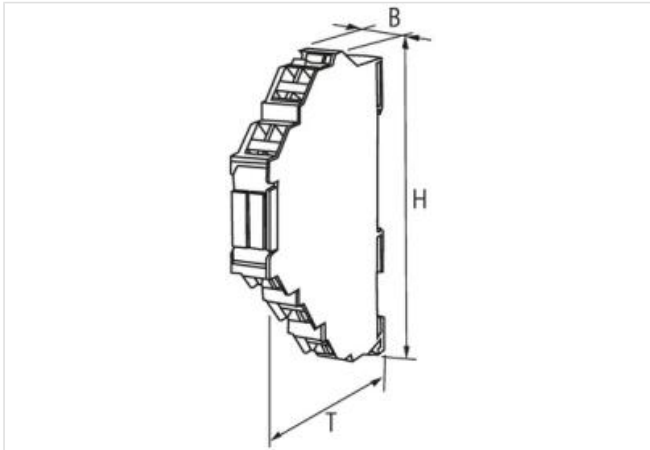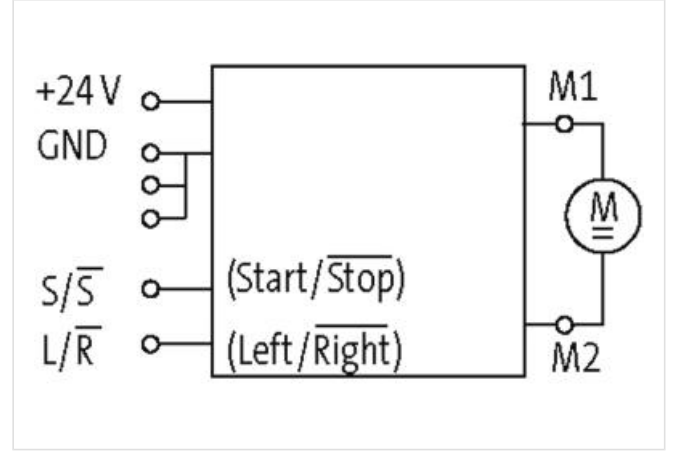

Ürün Image farklı olabilir



### Ticari bilgiler

|            |          |
|------------|----------|
| ECLASS-6.0 | 27371604 |
| ECLASS-6.1 | 27370905 |
| ECLASS-7.0 | 27370905 |
| ECLASS-8.0 | 27370905 |
| ECLASS-9.0 | 27370905 |

|                         |               |
|-------------------------|---------------|
| ECLASS-10.1             | 27370905      |
| ECLASS-11.1             | 27370905      |
| ECLASS-12.0             | 27370905      |
| ETIM-5.0                | EC002615      |
| GTIN                    | 4048879022279 |
| Gümrük tarife no (gtip) | 85365080      |
| Paket miktarı           | 1             |

**Electrical data | Input**

|                           |       |
|---------------------------|-------|
| Input voltage OFF DC min. | 0 V   |
| Input voltage OFF DC max. | 5 V   |
| Input voltage DC min.     | 15 V  |
| Input voltage DC max.     | 30 V  |
| Input current             | 10 mA |

**Electrical data | Output**

|                                          |                  |
|------------------------------------------|------------------|
| Switch off delay max.                    | 10 ms            |
| Switch on delay max.                     | 1,2 ms           |
| Quiescent current OFF max.               | 10 mA            |
| Additional condition switching frequency | engine dependent |
| Switching frequency max.                 | 1 Hz             |
| Voltage switching DC min.                | 19,2 V           |
| Switching voltage DC max.                | 30 V             |
| Switching current max.                   | 3 A              |
| Voltage drop DC max.                     | 1,4 V            |
| Highest current 100 ms                   | 6 A              |
| Turnaround time max.                     | 50 ms            |

**Diagnostics**

|                       |               |
|-----------------------|---------------|
| Status indication LED | green, yellow |
|-----------------------|---------------|

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data | Material data**

|                  |         |
|------------------|---------|
| Color housing    | black   |
| Material housing | Plastic |

**Mechanical data | Mounting data**

|                            |                                     |
|----------------------------|-------------------------------------|
| Mounting method            | geschnappt                          |
| Suitable for mounting type | Mounting rail TH35, G32, (EN 60715) |
| Height                     | 80 mm                               |
| Width                      | 12,4 mm                             |
| Depth                      | 70 mm                               |

**Environmental characteristics | Climatic**

|                            |       |
|----------------------------|-------|
| Operating temperature min. | 0 °C  |
| Operating temperature max. | 50 °C |