



MIRO 12.4 MULTI-TIMER

IN: 24 VAC/DC / 230 VAC - OUT: 230 VAC/DC / 6A

Relay output
Multitimer: 0.1...300
Spring clamp terminals

Ürün Linki

örnekleme

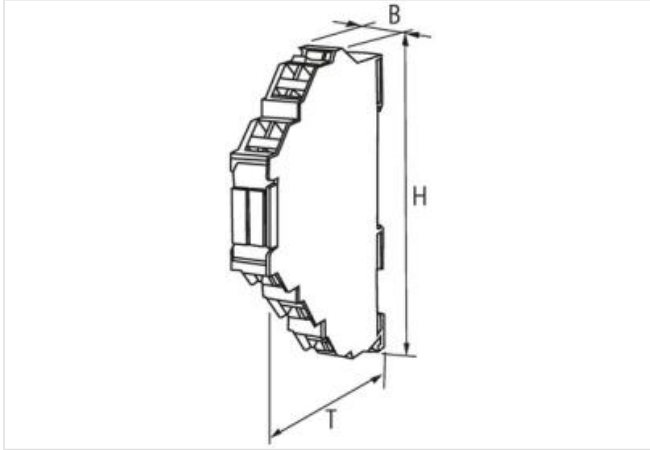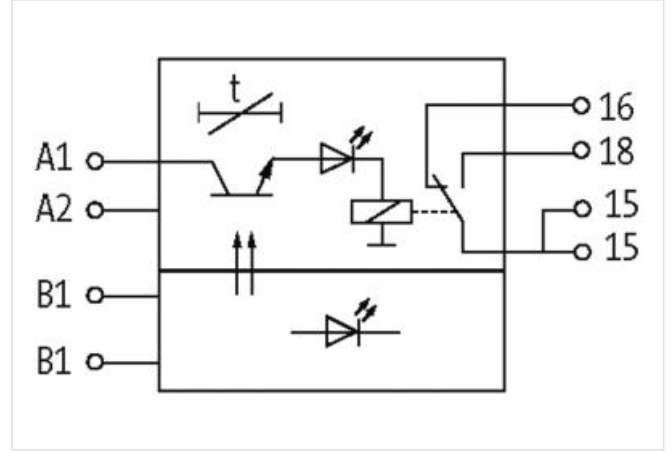

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371790
ECLASS-6.1	27371790
ECLASS-7.0	27371790
ECLASS-8.0	27371605
ECLASS-9.0	27371605
ECLASS-10.1	27371605

ECLASS-11.1	27371605
ECLASS-12.0	27371605
ETIM-5.0	EC002538
GTIN	4048879021890
Gümrük tarife no (gtip)	85364900
Paket miktarı	1
Electrical data Input	
Input voltage 1 AC	24 V
Input voltage 1 AC min.	20,4 V
Input voltage 1 AC max.	27,6 V
Input voltage 2 AC	220 V
Input voltage 2 AC min.	187 V
Input voltage 2 AC max.	253 V
Input voltage DC	24 V
Input voltage DC min.	20,4 V
Input voltage DC max.	27,6 V
Input current	12 mA
Input current DC max.	12 mA
Control voltage AC	230 V
Control voltage AC min.	195,5 V
Control voltage AC max.	264,5 V
Control voltage DC	24 V
Electrical data Output	
Output voltage adjustable	no
Output current max.	6 A
Power rating AC max.	1500 VA
Power rating DC max.	120 W
Switching voltage AC max.	230 V
Switching voltage DC max.	230 V
Switching current DC	8 mA
Device protection	
Condition lifetime	load-dependent
Device protection Electrical	
Rated surge voltage	4,8 kV
Electrical lifetime	20000000 Cycles
Device protection Mechanical	
Mechanical endurance	20000000 Cycles
Mechanical data	
Drop-out time max.	20 ms
Response time max.	8 ms
Bounce time max.	2 ms
Mechanical data Material data	
Material contact	Ag Sn O2
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	60 °C
Connection type 4	

Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	16
PIN 2	18
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	15
PIN 2	15
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	B 1
PIN 2	B 2
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	A 1
PIN 2	A 2