
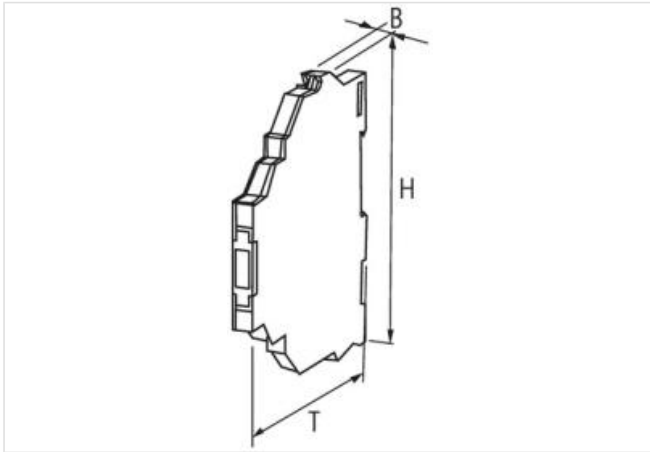


INDUCTIVCOUPLER 24V 5A 30KHZ

Inductive switching signal transmission
 Wear-free switching
 Spring clamp terminals
 No operating voltage at output
 Switching frequency: max. 30 kHz
 Switching current up to 5 A

Ürün Linki

örnekleme

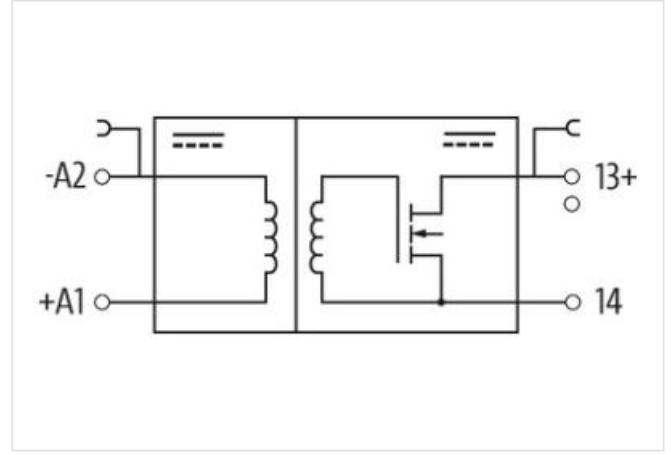

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27210990
ECLASS-6.1	27379090
ECLASS-7.0	27379090
ECLASS-8.0	27379090
ECLASS-9.0	27379090
ECLASS-10.1	27379090

ECLASS-11.1	27379090
ECLASS-12.0	27379090
ETIM-5.0	EC001504
GTIN	4048879329552
Gümrük tarife no (gtip)	85365080
Paket miktarı	1
Electrical data Input	
Input voltage OFF DC min.	0 V
Input voltage OFF DC max.	5 V
Input voltage DC	24 V
Input voltage DC min.	15 V
Input voltage DC max.	30 V
Input current DC max.	32 mA
Electrical data Output	
Quiescent current OFF max.	0,025 mA
Switching frequency inductive max.	3000 Hz
Switching frequency ohmic max.	30000 Hz
Switching current min.	1 mA
Switching current max.	5 A
Diagnostics	
Status indication LED	yellow
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Rated surge voltage	1,5 kV
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	78 mm
Width	6,2 mm
Depth	69 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C