
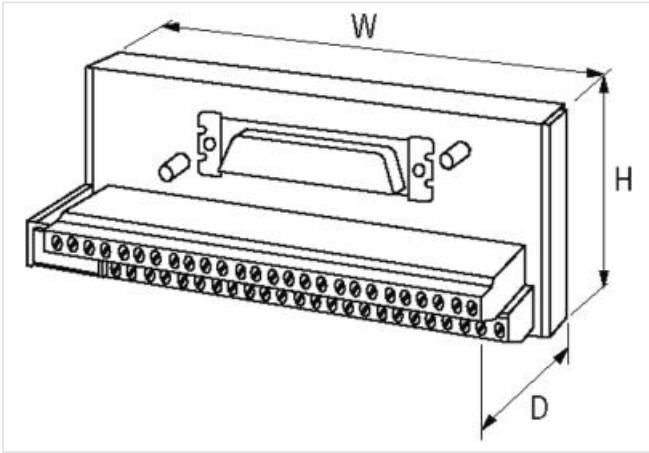


SV-SUB D 15BU.-KL FK

Female connector
15-pole
Spring clamp terminals

Ürün Linki

örnekleme

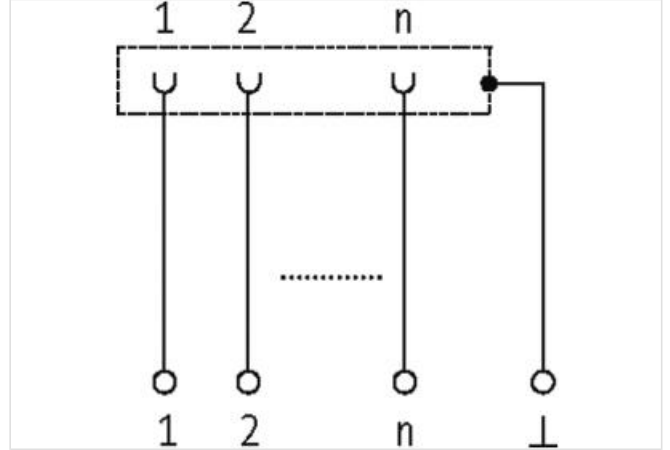

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27379201
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152

ETIM-5.0	EC001283
GTIN	4048879021579
Gümrük tarife no (gtip)	85366990
Paket miktarı	1
Electrical data Supply	
Operating voltage AC	125 V
Operating voltage DC	150 V
Operating current max.	2 A
Device protection Electrical	
Overvoltage category (EN 60664-1)	II
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	75 mm
Depth	48 mm
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C