

LUGS 24 FOR SIGNAL TRANSFER 250V/8 A



Mounting rail/pluggable spring clamps

24-pole

Push-In spring clamp terminals

Ürün Linki

örnekleme

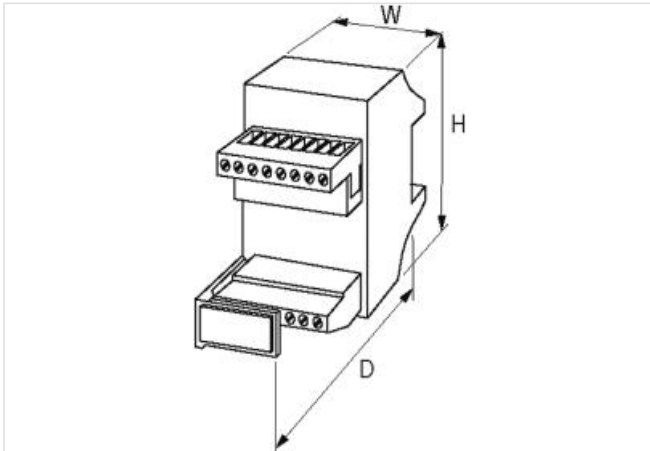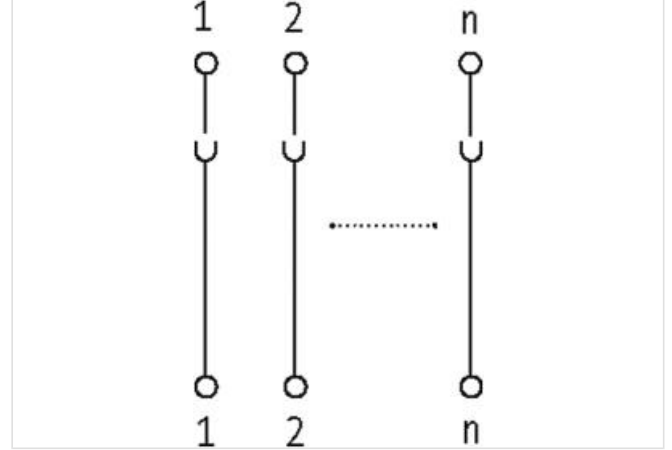

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27379201
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152

ETIM-5.0	EC001283
GTIN	4048879324137
Gümrük tarife no (gtip)	85369010
Paket miktarı	1
Electrical data Supply	
Operating voltage AC	250 V
Operating current max.	8 A
Installation	
Connection cross section max.	2,5 mm ²
AWG number	14
Installation Connection	
Connection	Spring clamp plug-in terminals
Device protection Electrical	
Overvoltage category (EN 50178)	I
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	70 mm
Depth	75 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C