

SIEMENS CONTACTOR SUPPRESSOR

Varistor and LED, 24VAC/DC

24 V AC/DC



48 V AC/DC

VDR + LED

For other configurations and voltages, please inquire.

Ürün Linki

örnekleme

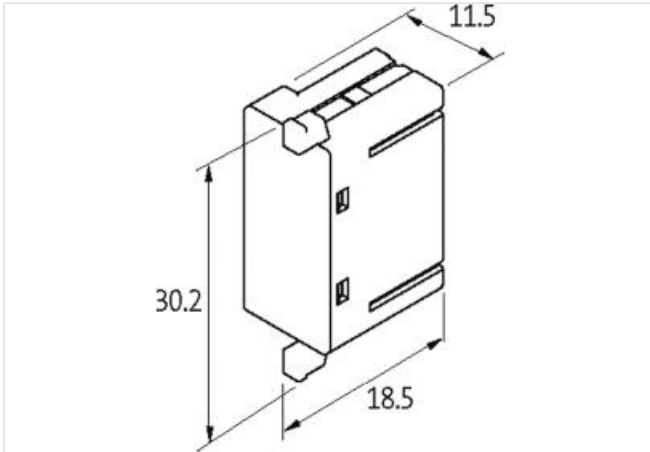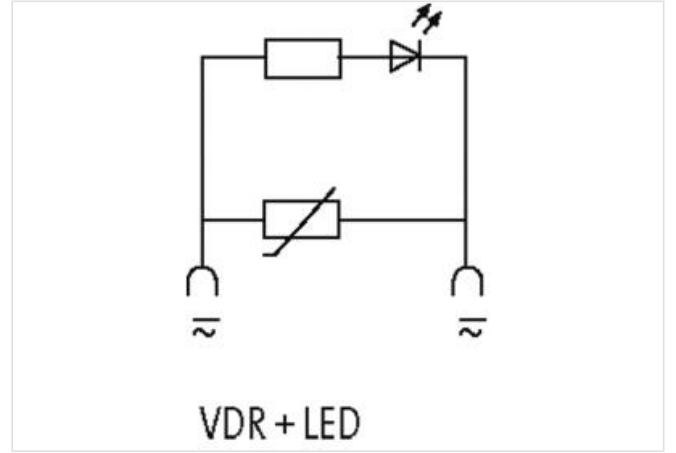

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
GTIN	4048879010825
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Compatibility Compatible with	
Appropriate contactors	3 RT 20.25/26/27/28
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	12 V
Input voltage AC max.	48 V
Input voltage DC min.	12 V
Input voltage DC max.	48 V
Installation Connection	
Connection information	Plug contact
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	18,5 mm
Width	30,2 mm
Depth	11,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C