

TELEMECANIQUE CONTACTOR SUPPRESSOR

Varistor, 230VAC/DC



230 V AC/DC

VDR

For other configurations and voltages, please inquire.

Ürün Linki

örnekleme

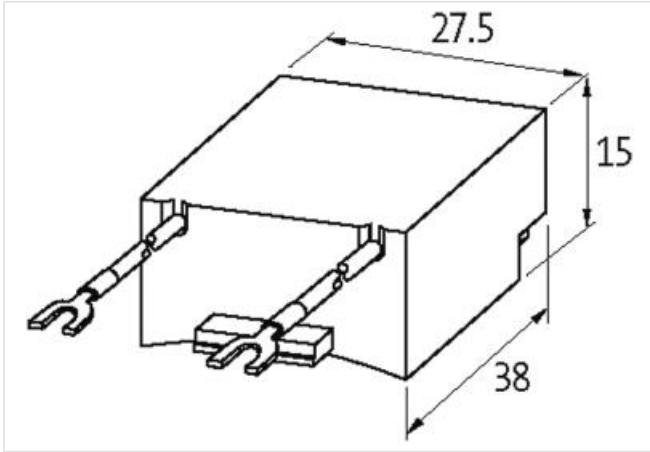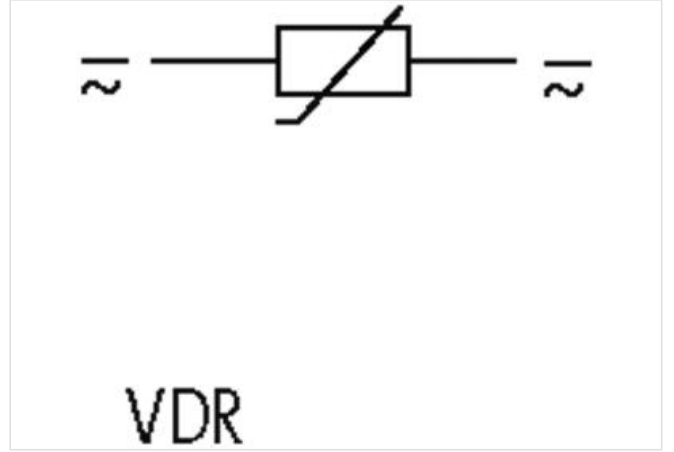

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
GTIN	4048879010238
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Compatibility Compatible with	
Appropriate contactors	DT40, LC 1 D09...D38, LC 1 DT20, LC 2 D09...D38
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	127 V
Input voltage AC max.	253 V
Input voltage DC min.	127 V
Input voltage DC max.	253 V
Installation Connection	
Connection information	self-securing cable forks
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	15 mm
Width	27,5 mm
Depth	38 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C