


MODLINK MSDD DBL COMBI INSERT USA 2XNEMA 5-15

GFCI without touch protection

2x NEMA-GFCI 5-15 (screw terminals)

Ürün Linki

örnekleme

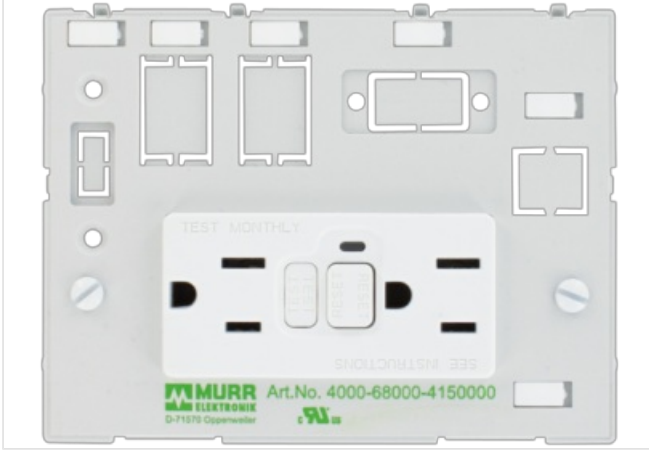

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
GTIN	4048879460453
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Mechanical data | Mounting data

Height	88 mm
Width	116 mm
Depth	43 mm

Environmental characteristics | Climatic

Storage temperature min.	-40 °C
Storage temperature max.	70 °C

USA

Connection cross section max.	6 mm ²
AWG number max.	10

Operating voltage AC	125 V
Operating current	15 A
Connection	Screw terminals SK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes