

MODLINK MSDD DBL COMBI INSERT GERMANY


RCD opening

1× Germany (VDE) white

1× FI cut-out

Ürün Linki

örnekleme

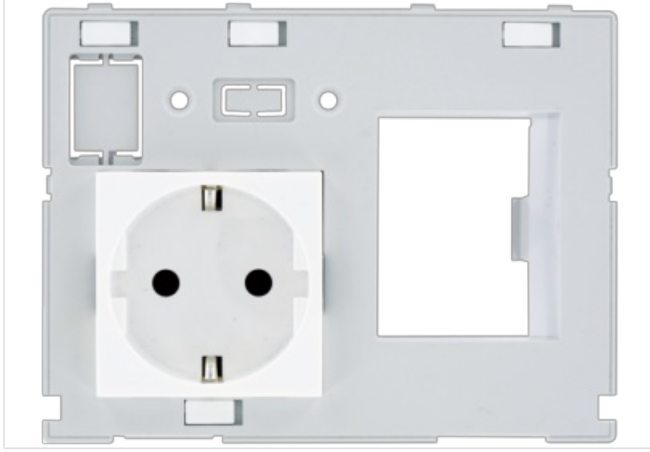

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
GTIN	4048879369350
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Mechanical data | Mounting data

Height	88 mm
Width	116 mm
Depth	70 mm

Environmental characteristics | Climatic

Storage temperature min.	-10 °C
Storage temperature max.	60 °C

Shielding plate

Connection information	Threaded hole M4
------------------------	------------------

Tightening torque 0,9 Nm

Germany (VDE)

Connection cross section max.	2,5 mm ²
AWG number max.	14
Operating voltage AC	250 V
Operating current	16 A
Connection	Spring clamp terminals FK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes