

MODLINK MSVD CABINET POWER OUTLETS

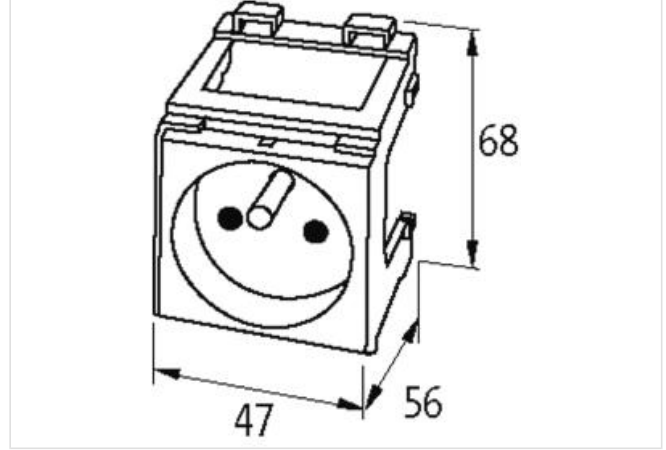
France (UTE) orange 250V AC / 16 A

France (UTE-NF) orange
Screw terminals**Ürün Linki**

örnekleme



Ürün Image farklı olabilir

**Electrical data | Supply**

Operating voltage AC	250 V
Operating current min.	10 A
Operating current max.	16 A

Installation

Connection cross section max.	2,5 mm ²
AWG number max.	14

Installation | Connection

Connection	Spring clamp terminals FK
------------	---------------------------

Installation | Pin assignment

Connections per pole	2
----------------------	---

Mechanical data | Mounting data

Mounting method	Snap-in connector
Suitable for mounting type	Mounting rail TH35
Height	68 mm
Width	47 mm
Depth	56 mm

Ticari bilgiler

GTIN	4048879031264
Gümrük tarife no (gtip)	85366990
Paket miktarı	1