

MODLINK MSVD CABINET POWER OUTLETS

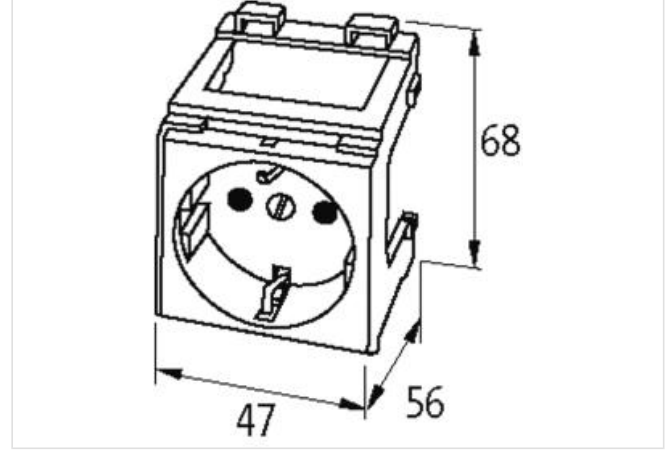
VDE 250V AC / 16 A, spring clamp terminals

Germany (VDE) white
Spring clamp terminals**Ürün Linki**

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27143423
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC002625
GTIN	4048879031257
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage AC	250 V
Operating current	16 A

Installation

Connection cross section max.	2,5 mm ²
AWG number max.	14

Installation | Connection

Connection	Spring clamp terminals FK
------------	---------------------------

Installation | Pin assignment

No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes
Mechanical data Mounting data	
Mounting method	Snap-in connector
Suitable for mounting type	Mounting rail TH35
Height	68 mm
Width	47 mm
Depth	56 mm