

MODLINK MSVD CABINET POWER OUTLETS

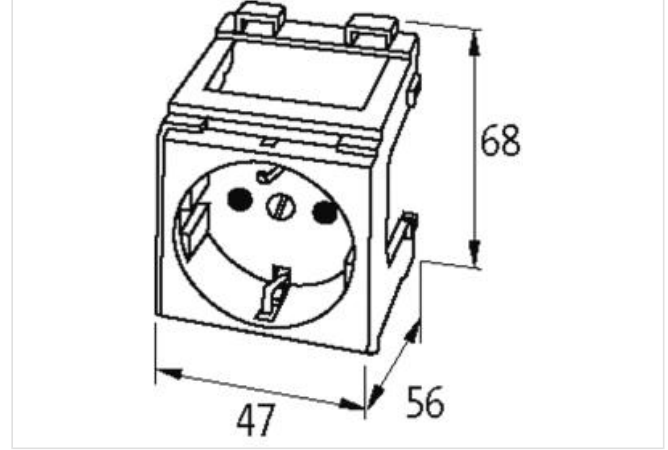
Denmark 250V AC / 13 A, spring clamp terminals

Denmark (white)
Spring clamp terminals**Ürün Linki**

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27143423
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC002625
GTIN	4048879031240
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage AC	250 V
Operating current	13 A

Installation

Connection cross section max.	2,5 mm ²
AWG number	14

Installation | Connection

Connection	Spring clamp plug-in terminals
------------	--------------------------------

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	68 mm
Width	47 mm
Depth	56 mm