







MSDD pass-through RJ45 CAT6A femal/femal, design silver

Pass-through

1 x RJ45, 8-pole metal, CAT6A (female/female)

Ürün Linki

örnekleme

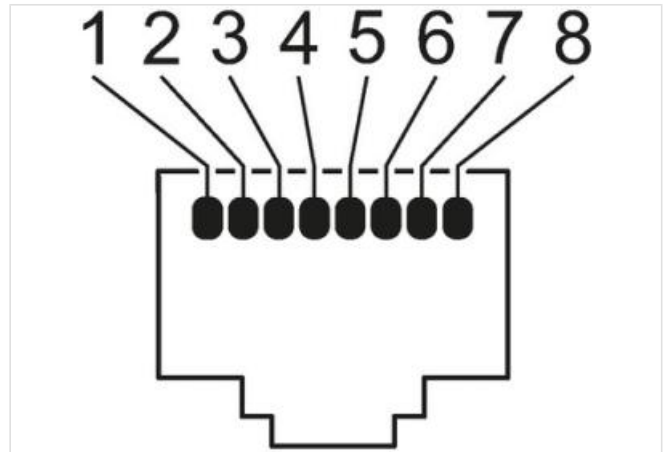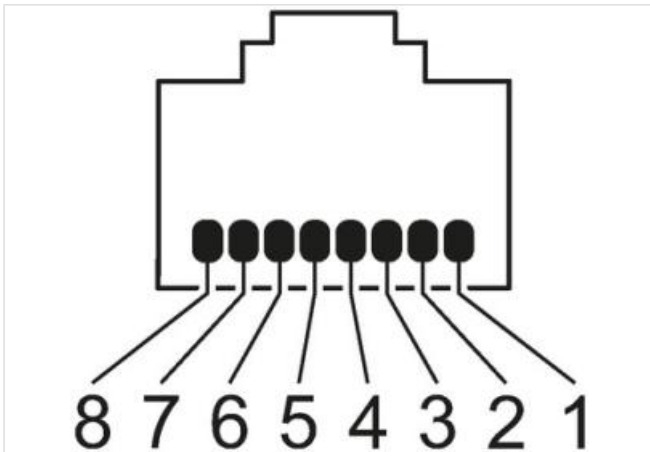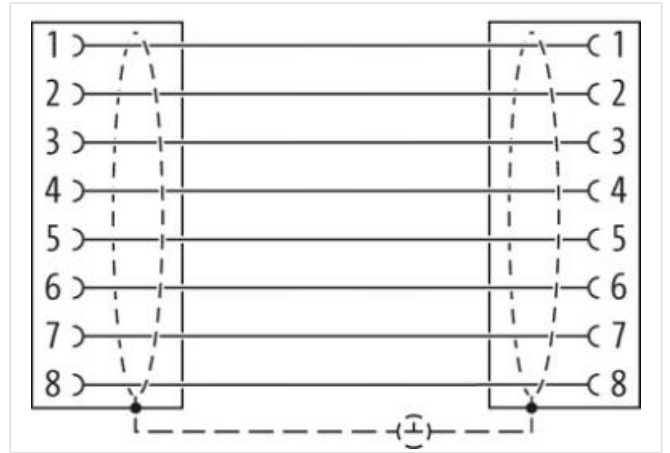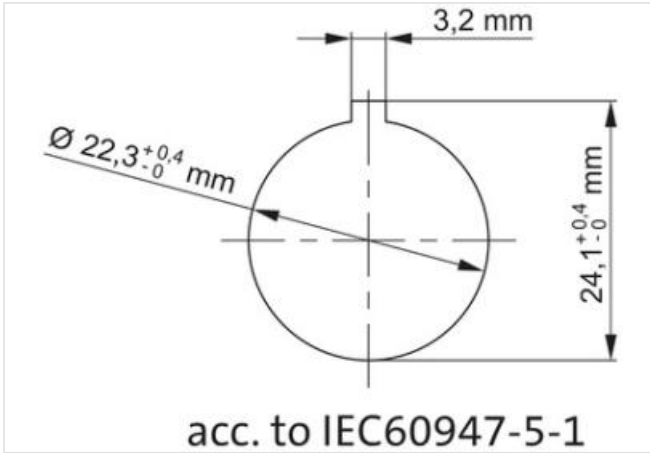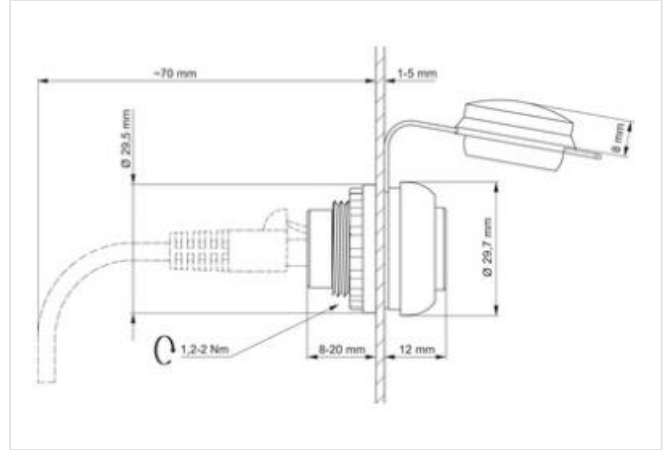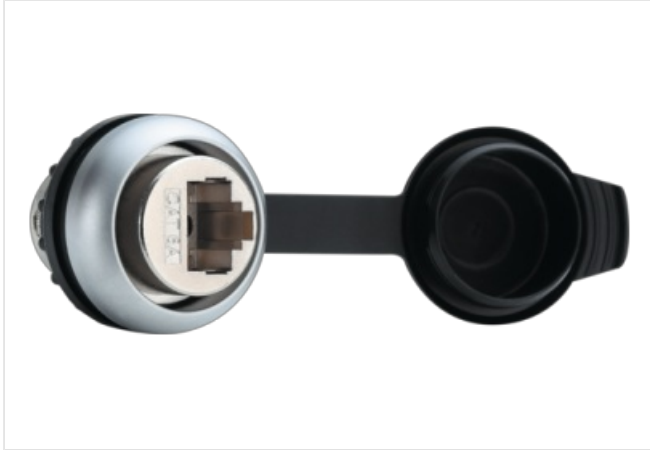

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
GTIN	4065909037256
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage AC	24 V
Operating voltage DC	24 V
Operating current max.	1,5 A

Installation | Connection

Family construction form	RJ45
Gender	female
Gender Rear	female
Cable category min.	Cat6a

Device protection

Shielded	yes
----------	-----

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state

Device protection | Mechanical

Mechanical endurance	750 Cycles
----------------------	------------

Mechanical data | Mounting data

Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	20 mm

Approvals

UL 50E	yes
--------	-----