

AIDA PUSH PULL COUPLING HAN24

with power (5 pole) spring clamp + RJ45 fem/fem

with RJ45 and energy

1 × RJ45, 8-pole metal, CAT5e (female/female)


Combicon Power/spring clamp terminal, Push Pull
Size 24

Ürün Linki

örnekleme



Ürün Image farklı olabilir

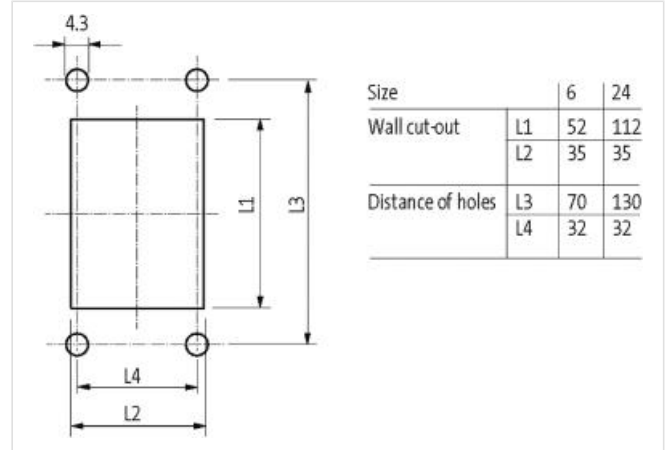

Ticari bilgiler

ECLASS-6.0	27143423
ECLASS-6.1	27143423
ECLASS-7.0	27449001
ECLASS-8.0	27449001
ECLASS-9.0	27440321
ECLASS-10.1	27440321
ECLASS-11.1	27440321
ECLASS-12.0	27440321
ETIM-5.0	EC002625
GTIN	4048879031165
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Mechanical data | Material data

Material housing	PA
------------------	----

Mechanical data | Mounting data

Height	146 mm
Width	58 mm
Depth	65 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	70 °C