

AIDA PUSH PULL COUPLING HAN24

with power (5 pole) spring clamp + SCRJ


with fiber optic and energy
Combicon Power/spring clamp terminal, Push Pull
Size 24

Ürün Linki

örnekleme



Ürün Image farklı olabilir

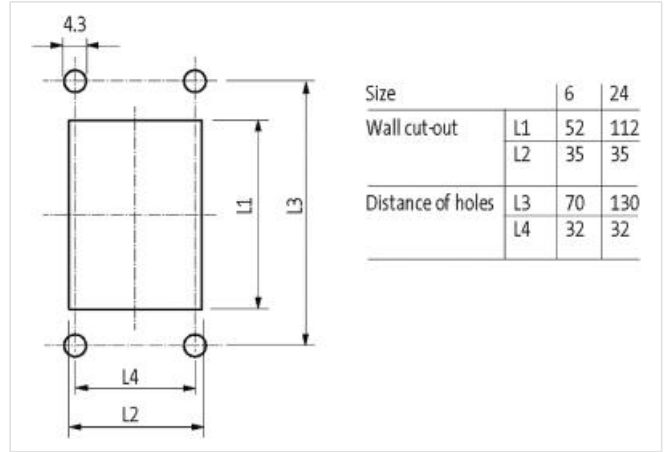

Ticari bilgiler

ECLASS-6.0	27143423
ECLASS-6.1	27143423
ECLASS-7.0	27449001
ECLASS-8.0	27449001
ECLASS-9.0	27440321
ECLASS-10.1	27440321
ECLASS-11.1	27440321
ECLASS-12.0	27440321
ETIM-5.0	EC002625
GTIN	4048879031158
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Mechanical data | Material data

Material housing	PA
------------------	----

Mechanical data | Mounting data

Height	146 mm
Width	58 mm
Depth	52 mm

Environmental characteristics | Climatic

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.
Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalî sınırlıdır. Sürüm: 2024-05-21

Operating temperature min.	-25 °C
Operating temperature max.	70 °C