


MODLIGHT70 CONNECTION MODULE 8 POLE M12 SIDE EXIT

Product discontinued

Ürün Linki

örnekleme

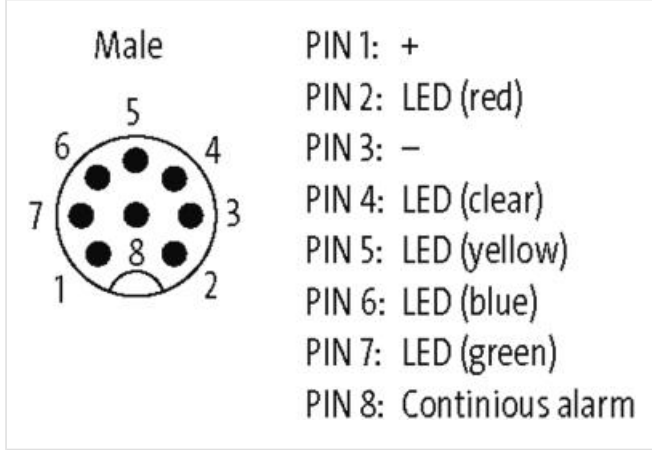

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ETIM-5.0	EC001155
GTIN	4048879030823
Gümrük tarife no (gtip)	85319000
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked

Mechanical data | Material data

Color housing	black
Material housing	Plastic

Mechanical data | Mounting data

Height	190 mm
Width	70 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	60 °C

Connection type 1

Family construction form	M12
Gender	male

Coding	A
No. of poles	8
PIN 1	+
PIN 2	LED RD
PIN 3	-
PIN 4	LED CL
PIN 5	LED YE
PIN 6	LED BU
PIN 7	LED GN
PIN 8	Continuous tone