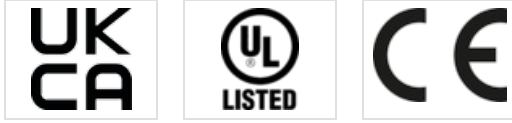
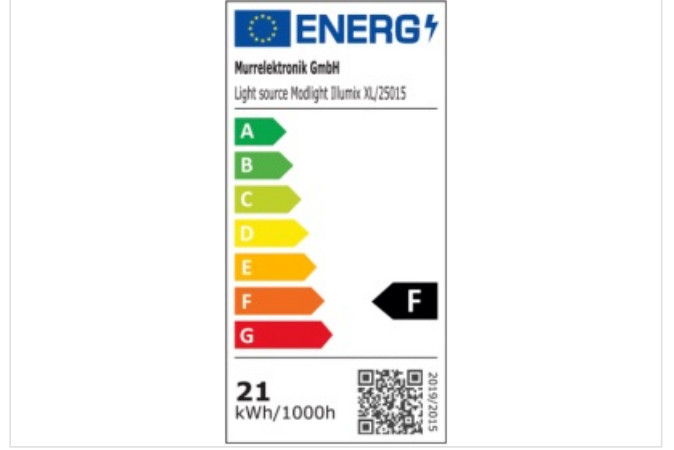


Modlight Illumix Xtreme Line 27W

LED machine lamp, IP69K, 24VDC, M12 connection

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27110303
ECLASS-6.1	27110390
ECLASS-7.0	27110390
ECLASS-8.0	27110390
ECLASS-9.0	27110345
ECLASS-10.1	27110345
ECLASS-11.1	27110345
ECLASS-12.0	27110345
ETIM-5.0	EC001334
GTIN	4048879439169
Gümrük tarife no (gtip)	94054239
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Current consumption max.	1120 mA

HMI | Illumination properties

Illumination level	860 lx
--------------------	--------

Installation | Connection

Family construction form	M12
--------------------------	-----

Installation | Pin assignment

No. of poles	5
--------------	---

Device protection | Electrical

Degree of protection (ISO 20653:2013)	IP69K
Additional condition protection degree	inserted, screwed
Mechanical data Material data	
Housing properties	with stainless steel cover
Material housing	Aluminium
Mechanical data Mounting data	
Height	43 mm
Width	97 mm
Depth	441 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	55 °C