

Modlight70 Pro connecting modul 5 pole M12

downward, Input 24VDC

Basic

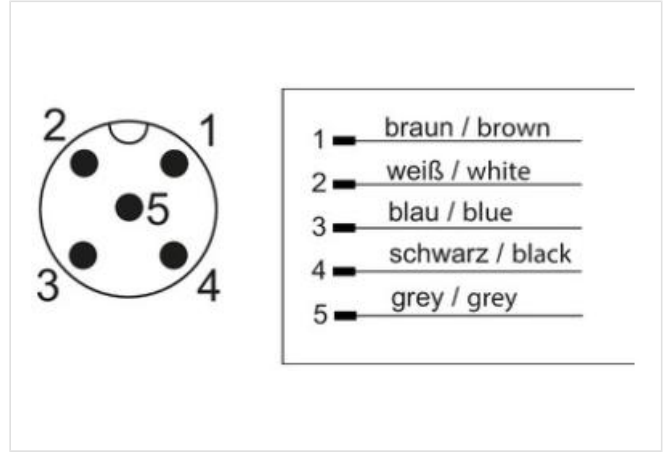
with M12 connection

Outlet on the bottom

Connection cables are in the online shop under "Connection Technology".

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
GTIN	4048879758888
Gümrük tarife no (gtip)	85319000
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Additional condition protection degree inserted, locked

Mechanical data | Material data

Color housing black

Material housing Plastic

Mechanical data | Mounting data

Height 140 mm

Width 70 mm

Depth 70 mm

Environmental characteristics | Climatic

Operating temperature min. -30 °C

Operating temperature max. 60 °C

Connection type 1

Mounting method bayonet-locking