

Modlight70 Pro connecting modul 8 pole M12

side, Input 24VDC

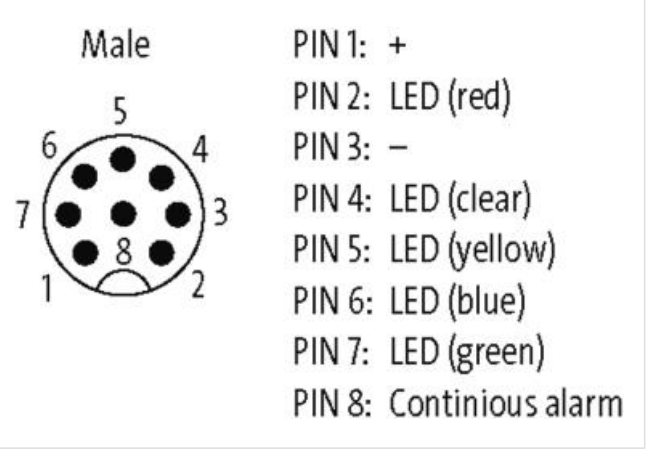
Basic

Outlet on the side
with M12 connection

Connection cables are in the online shop under "Connection Technology".

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
GTIN	4048879758895
Gümrük tarife no (gtip)	85319000
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Additional condition protection degree inserted, locked

Mechanical data | Material data

Color housing black
Material housing Plastic

Mechanical data | Mounting data

Height 122 mm
Width 88 mm
Depth 70 mm

Environmental characteristics | Climatic

Operating temperature min. -30 °C
Operating temperature max. 60 °C

Connection type 2

Family construction form M12
Gender male
Coding A
No. of poles 8
PIN 1 24 V DC / 0 V
PIN 2 LED-Modul RD
PIN 3 0 V / 24 V DC
PIN 4 LED-Modul CL
PIN 5 LED-Modul YE
PIN 6 LED-Modul BU
PIN 7 LED-Modul GN
PIN 8 Buzzer
Mounting method bayonet-locking