

Signal tower Modlight70 Pro equipped with LED modules

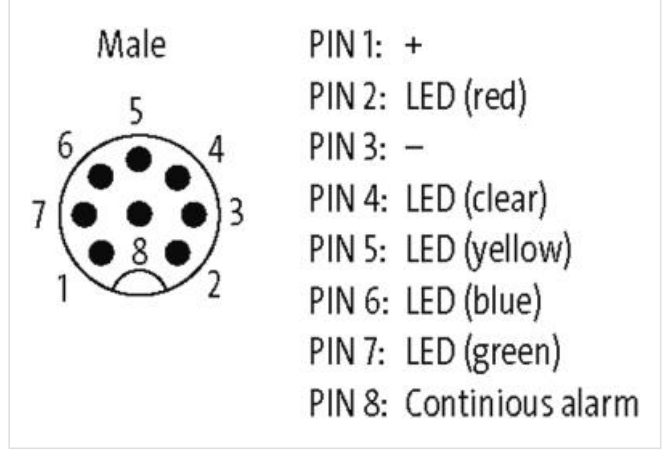
green,amber,red,buzzer,M12 plug downward

Basic, buzzer, flash + LED modules + M12 (down)
green, yellow, red**Ürün Linki**

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371230
ECLASS-6.1	27371230
ECLASS-7.0	27371230
ECLASS-8.0	27371230
ECLASS-9.0	27371230
ECLASS-10.1	27371230
ECLASS-11.1	27371230
ECLASS-12.0	27371230
ETIM-5.0	EC001042
GTIN	4048879759939
Gümrük tarife no (gtip)	85318070
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Current consumption max.	385 mA

Industrial communication | HMI

Buzzer sound	fast beep, continuous beep, fast high-low, sweep tone
Reduced sound pressure at 1 m	80 dB
Sound pressure at 1 m	90 dB

HMI | Illumination properties

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.
Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalî sınırlıdır. Sürüm: 2024-04-24

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Blink cycles 60 ±12 per minute

Device protection | Electrical

Degree of protection (EN IEC 60529) IP65
Additional condition protection degree inserted, locked

Mechanical data | Material data

Color housing black
Material housing Plastic

Mechanical data | Mounting data

Height 293 mm
Width 70 mm
Depth 70 mm

Environmental characteristics | Climatic

Operating temperature min. -30 °C
Operating temperature max. 60 °C