

Signal tower Modlight70 Pro equipped with LED modules

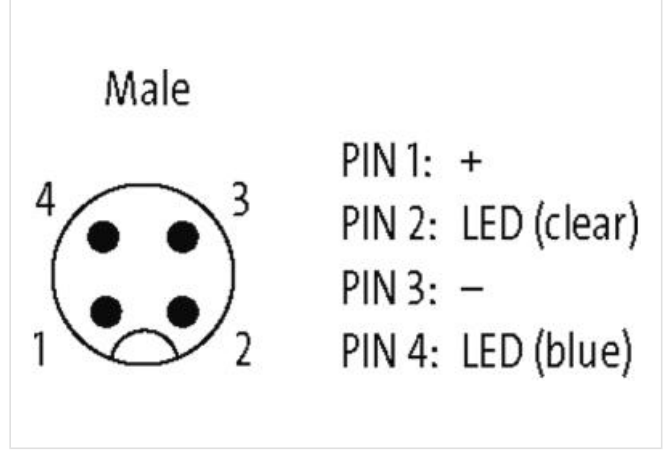
blue,clear,M12 plug downward

Basic + LED modules + M12 (down)
blue, clear**Ürün Linki**

örnekleme



Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371230
ECLASS-6.1	27371230
ECLASS-7.0	27371230
ECLASS-8.0	27371230
ECLASS-9.0	27371230
ECLASS-10.1	27371230
ECLASS-11.1	27371230
ECLASS-12.0	27371230
ETIM-5.0	EC001042
GTIN	4048879759960
Gümrük tarife no (gtip)	85318070
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Current consumption max.	90 mA

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked

Mechanical data | Material data

Color housing	black
---------------	-------

Material housing Plastic

Mechanical data | Mounting data

Height	179 mm
Width	70 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	50 °C

Connection type 2

Family construction form	M12
Gender	male
Coding	A
No. of poles	4
PIN 1	24 V DC (0 V)
PIN 2	LED-Modul CL
PIN 3	0 V (24 V DC)
PIN 4	LED-Modul BU
Mounting method	bayonet-locking