

M12 male 90° A-cod. screw terminal5-pol., 0,14 - 1,5mm², 2,5 - 8mm

Male 90°

M12, 5-pole



Screw terminals

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

Ürün Linki

örnekleme

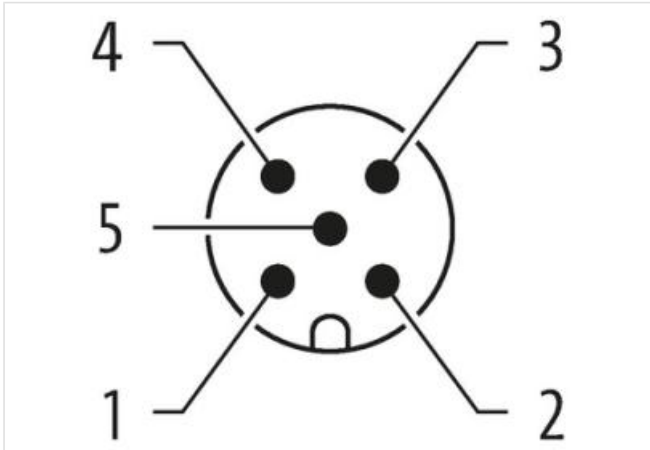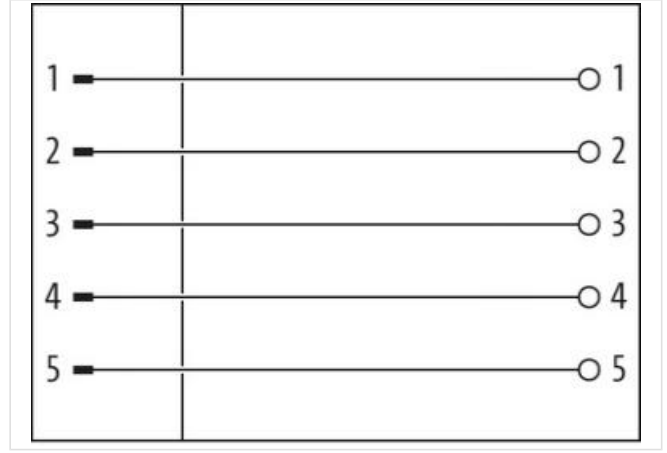

Ürün Image farklı olabilir

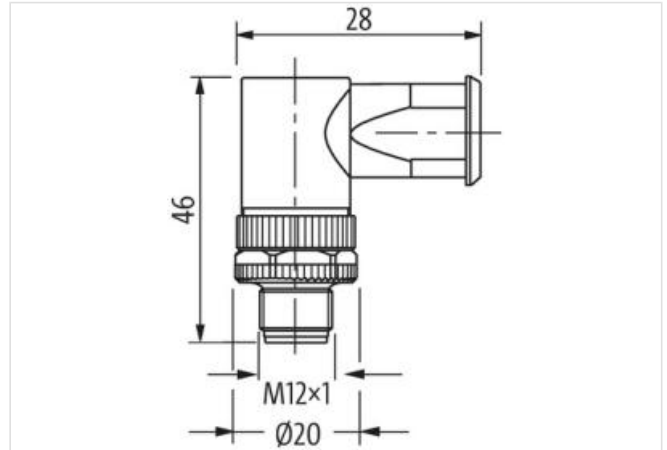**Side 1**

Family construction form M12

Degree of protection (EN IEC 60529) IP67

Ticari bilgiler

ECLASS-6.0 27279221

ECLASS-6.1	27260702
ECLASS-7.0	27440102
ECLASS-8.0	27440102
ECLASS-9.0	27440116
ECLASS-10.1	27440102
ECLASS-11.1	27440102
ECLASS-12.0	27440116
ETIM-5.0	EC002635
GTIN	4048879438247
Gümrük tarife no (gtip)	85366990
Paket miktarı	1
Electrical data Supply	
Operating voltage AC max.	60 V
Operating voltage DC max.	60 V
Operating current per contact max. (40°C)	7,5 A
Installation	
Connection cross section max.	1,5 mm ²
Installation Connection	
Tightening torque	0,6 Nm
Device protection Electrical	
Additional condition protection degree	inserted, screwed
Mechanical data Mounting data	
Mounting method	Schraubgewinde
Clamping range min.	2,5 mm
Clamping range max.	8 mm
Height	46 mm
Width	38 mm
Depth	20 mm
Environmental characteristics Climatic	
Operating temperature min.	-30 °C
Operating temperature max.	85 °C