

M12 MALE 0° SHIELDED WIREABLE SCREW TERM.5-pol. max.0,75mm² 4-6mm

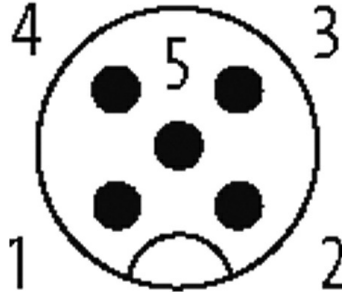
Düz erkek soket
M12, 5 kutuplu
blendajlı
Vidalı klemensler
Klemens alanı (kablo Ø): 4...6 mm

Ürün Linki

örnekleme



Male



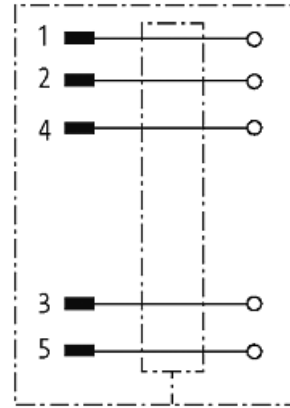
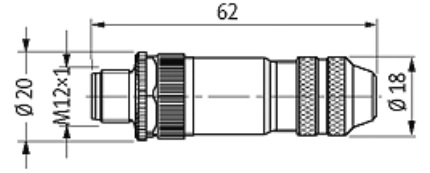
Ürün Image farklı olabilir

Form	
Form	13301
General data	
Temperature range	-40...+85 °C
Technical Data	
Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	4...6 mm
Protection	IP67 takılı ve vidalı konumda (EN 60529)
Housing	Pirinç, nikelajlı
Ticari bilgiler	
EAN	4048879198844
eClass	27279221

Gümrük tarife no (gtip) 85366990

Menşei DE

Paket miktarı 1

kroki

Ürün Image farklı olabilir