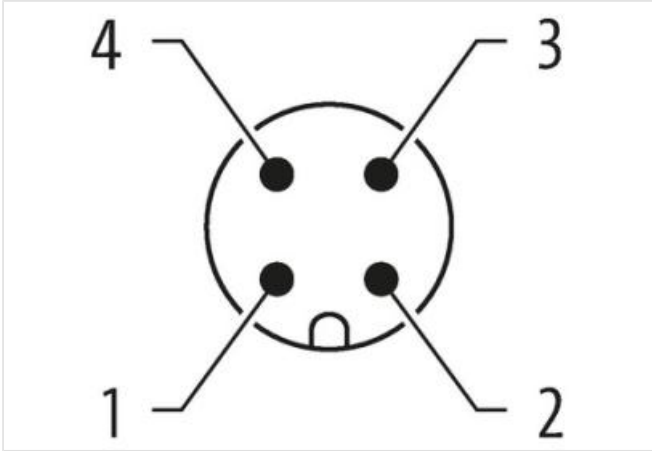
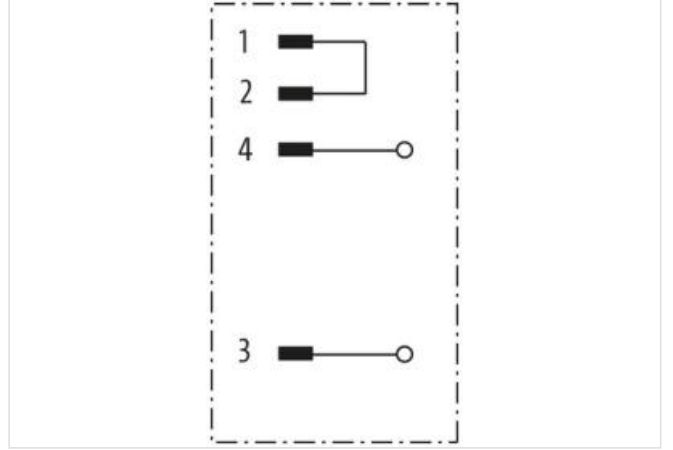
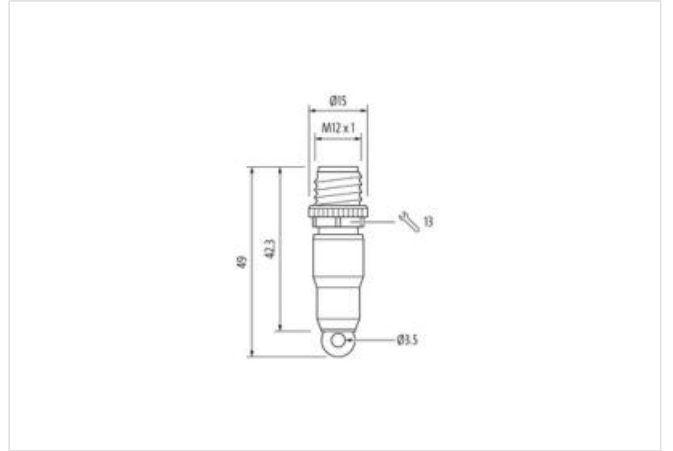


M12 MALE 0° DIAGNOSTIC PLUG DESINA

Blind plug diagnostic M12×1 mm
Bridge PIN 1 + 2

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	23111190
ECLASS-6.1	27260702
ECLASS-7.0	27440390
ECLASS-8.0	27440190
ECLASS-9.0	27440190
ECLASS-10.1	27440190
ECLASS-11.1	27440190
ECLASS-12.0	27440190
ETIM-5.0	EC001855

GTIN	4048879198745
------	---------------

Gümrük tarife no (gtip)	85366990
-------------------------	----------

Paket miktarı	1
---------------	---

Electrical data | Supply

Operating voltage AC max.	30 V
---------------------------	------

Operating voltage DC max.	30 V
---------------------------	------

Operating voltage AC max. (UL-listed)	30 V
---------------------------------------	------

Operating voltage DC max. (UL-listed)	30 V
---------------------------------------	------

Current operating per contact max.	4 A
------------------------------------	-----

Installation | Connection

Tightening torque	0,6 Nm
-------------------	--------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Additional condition protection degree	screwed, mounted
--	------------------

Mechanical data | Material data

Coating locking	Nickel
-----------------	--------

Locking material	Zinc die-casting
------------------	------------------

Mechanical data | Mounting data

Mounting method	inserted, screwed, Shaking protection
-----------------	---------------------------------------