

M12 male 0° B-cod. screw terminal shielded2-pol., max. 0.75mm², 6 - 8mm, shielded**PROFIBUS**

Male straight

M12, 2-pole

B-coded

shielded

Screw terminals

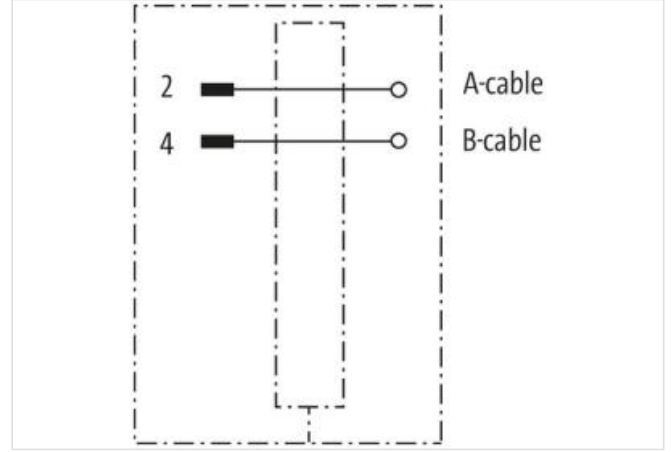
Sealing range (cable Ø): 6...8 mm

Ürün Linki

örnekleme



Ürün Image farklı olabilir

**Side 1**

Family construction form	M12
Degree of protection (EN IEC 60529)	IP67

Ticari bilgiler

ECLASS-6.0	27279221
ECLASS-6.1	27260702
ECLASS-7.0	27440102
ECLASS-8.0	27440102
ECLASS-9.0	27440116
ECLASS-10.1	27440102
ECLASS-11.1	27440102
ECLASS-12.0	27440116
ETIM-5.0	EC002635
GTIN	4048879198646
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage AC max.	60 V
Operating voltage DC max.	60 V
Current operating per contact max.	4 A

Installation

Connection cross section max.	0,75 mm ²
-------------------------------	----------------------

Device protection | Electrical

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.

Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalî sınırlıdır. Sürüm: 2024-04-20

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Additional condition protection degree inserted, screwed

Mechanical data | Material data

Coating housing nickel plated

Material housing Brass

Mechanical data | Mounting data

Clamping range min. 6 mm

Clamping range max. 8 mm

Environmental characteristics | Climatic

Operating temperature min. -25 °C

Operating temperature max. 85 °C