

### Adaptor M8 male / M8 female A-cod.

4-pol. / 3-pol., conf. 1,3,4



Adapter

Male - female


M8 – M8, 4/3-pole

### Ürün Linki

örnekleme

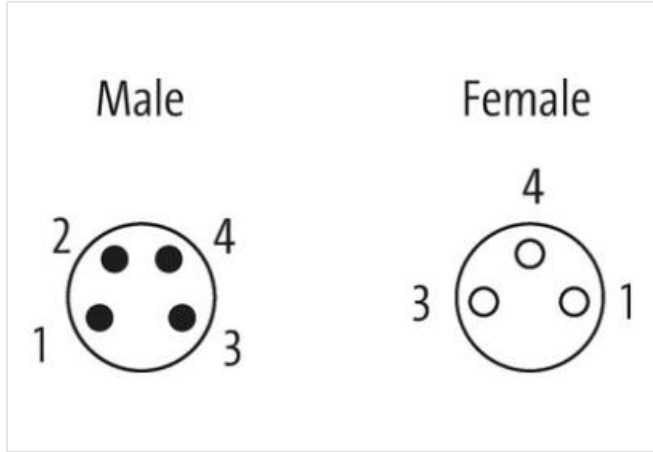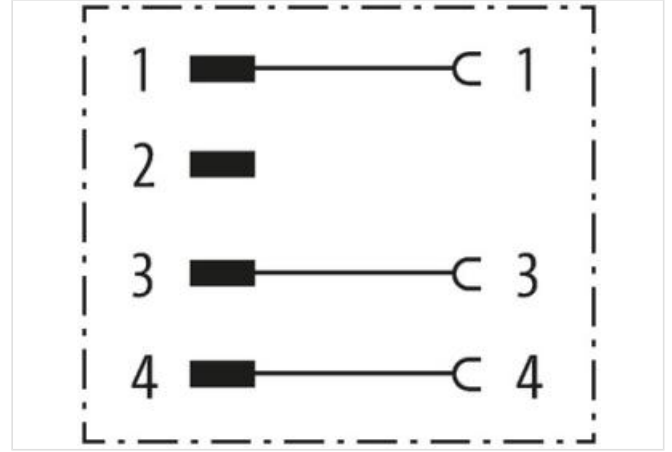

Ürün Image farklı olabilir

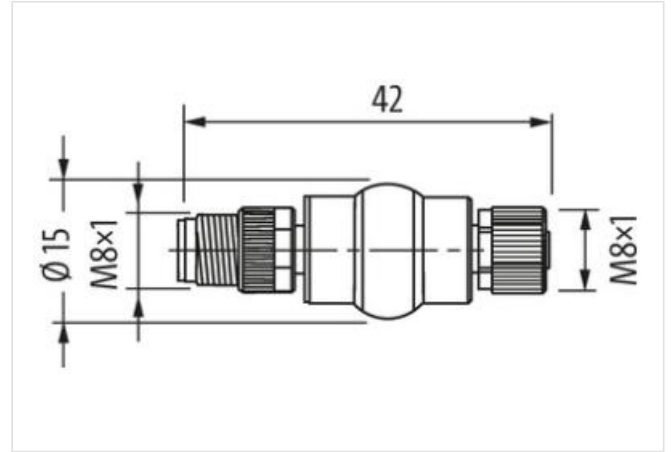

### Ticari bilgiler

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27143423 |
| ECLASS-7.0  | 27449001 |
| ECLASS-8.0  | 27449001 |
| ECLASS-9.0  | 27440321 |
| ECLASS-10.1 | 27440102 |
| ECLASS-11.1 | 27440102 |

|                                                 |                                       |
|-------------------------------------------------|---------------------------------------|
| ECLASS-12.0                                     | 27440106                              |
| ETIM-5.0                                        | EC001855                              |
| GTIN                                            | 4048879118545                         |
| Gümrük tarife no (gtip)                         | 85366990                              |
| Paket miktarı                                   | 1                                     |
| <b>Electrical data   Supply</b>                 |                                       |
| Operating voltage AC max.                       | 50 V                                  |
| Operating voltage DC max.                       | 50 V                                  |
| Operating voltage AC max. (UL-listed)           | 30 V                                  |
| Operating voltage DC max. (UL-listed)           | 30 V                                  |
| Current operating per contact max.              | 4 A                                   |
| <b>Installation   Connection</b>                |                                       |
| Tightening torque                               | 0,6 Nm                                |
| Mounting set                                    | M12 x 1                               |
| <b>Device protection   Electrical</b>           |                                       |
| Degree of protection (EN IEC 60529)             | IP67                                  |
| Additional condition protection degree          | inserted, screwed                     |
| Rated insulation voltage                        | 800 V                                 |
| Rated surge voltage                             | 1,5 kV                                |
| <b>Mechanical data   Material data</b>          |                                       |
| Coating locking                                 | Nickel                                |
| Material housing                                | PUR                                   |
| Locking material                                | Zinc die-casting                      |
| <b>Mechanical data   Mounting data</b>          |                                       |
| Mounting method                                 | inserted, screwed, Shaking protection |
| <b>Environmental characteristics   Climatic</b> |                                       |
| Operating temperature min.                      | -25 °C                                |
| Operating temperature max.                      | 85 °C                                 |