

Valve connector base A-18mm

2-pol.+ PE

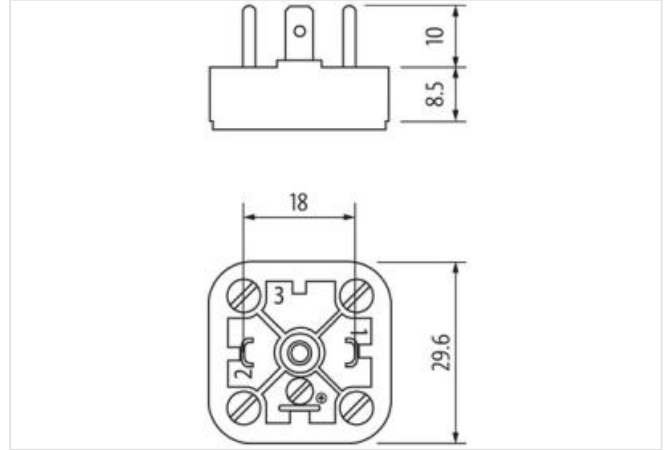
Valve plug socket
Form A (18 mm)
2 contacts + PE

Ürün Linki

örnekleme



Ürün Image farklı olabilir

**Side 1**

Material contact Brass

Ticari bilgiler

ECLASS-6.0	27279220
ECLASS-7.0	27440103
ECLASS-8.0	27440103
ECLASS-9.0	27440103
ECLASS-10.1	27440105
ECLASS-11.1	27440105
ECLASS-12.0	27440105
ETIM-5.0	EC001855
GTIN	4048879114059
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	30 V
Operating current	10 A

Installation

Connection cross section max.	1 mm ²
-------------------------------	-------------------

Installation | Connection

Connection information	Lötanschluss
------------------------	--------------

Installation | Pin assignment

No. of poles	2 + PE
--------------	--------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Pollution Degree	3
Rated surge voltage	4 kV
Overvoltage category (EN 60664-1)	III
Overvoltage category (EN 60950-1)	III
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Coating contact	tin-plated
Material contact carrier	Plastic
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	125 °C