

A3 female 3-pole, Push-in, 400 V, 10 A

A3

Female

3-pole

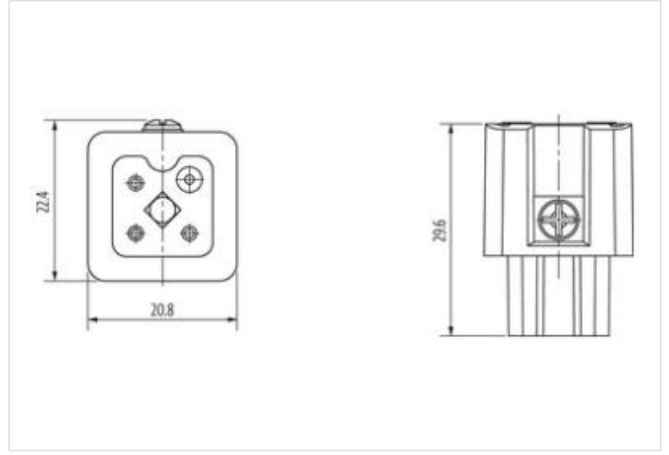
Push-In terminals

Technical data will be only guaranteed with Murrelektronik components.

Please use wire end ferrule.

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27143424
ECLASS-6.1	27261204
ECLASS-7.0	27440205
ECLASS-8.0	27440205
ECLASS-9.0	27440205
ECLASS-10.1	27440205
ECLASS-11.1	27440205
ECLASS-12.0	27440205
ETIM-5.0	EC000438
GTIN	4048879764186
Gümrük tarife no (gtip)	85366990
Paket miktarı	1

Electrical data | Supply

Operating voltage AC per power contact max.	400 V
Operating voltage AC per signal contact max.	230 V
Operating voltage DC per power contact max.	400 V
Operating voltage DC per signal contact max.	230 V
Operating current	10 A

Installation

Connection cross section min.	0,14 mm²
-------------------------------	----------

Connection cross section max. 1,5 mm²

Installation | Connection

Stripping length 10 mm

Connection Push-In spring clamp terminals

Gender female

Mating cycles min. 500

Installation | Pin assignment

No. of poles 3 + PE

Device protection | Electrical

Pollution Degree 3

Rated surge voltage 4 kV

Overvoltage category (EN 60950-1) III

Mechanical data | Material data

Coating contact silver-plated

Combustibility class (UL94) V-0

Material contact carrier PC

Mechanical data | Mounting data

Size A3

Height 29,6 mm

Width 20,8 mm

Depth 22,4 mm

Environmental characteristics | Climatic

Operating temperature min. -40 °C

Operating temperature max. 125 °C

Climatic category (EN IEC 60068-1) 40/125/21