

B16 Surface mounted h., high profile, IP65

Double locking lever m.,2 entries M32

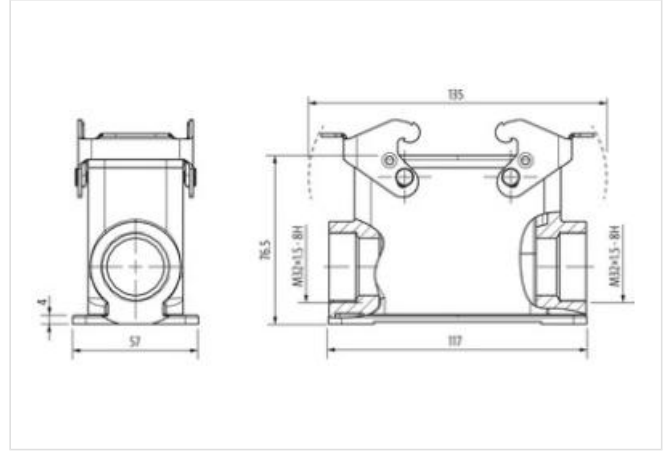
B16

Surface mounted housing (high)

Double locking lever

IP65

Technical data will be only guaranteed with Murrelektronik components.

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
GTIN	4048879646543
Gümrük tarife no (gtip)	85389099
Paket miktarı	1

Installation

Cable outlet	double-sided
--------------	--------------

Installation | Connection

Mounting set	M32
Mating cycles min.	500

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection

Mechanical data

Housing type	Surface mounted housing
--------------	-------------------------

Mechanical data | Material data

Coating housing	powder-coated
Coating locking	verzinkt
Material gasket	NBR
Material housing	Aluminum die casting
Locking material	Steel

Mechanical data | Mounting data

Size	B16
Height	76,5 mm
Width	57 mm
Depth	117 mm
Looking techniques	Double locking lever

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	100 °C
Climatic category (EN IEC 60068-1)	40/100/21