

EXACT12, 8XM12, 4 POLE, CON. M23 12 POLE

Without con. cable

8-way, 4-pole

M23 plug connection

12-pole used



with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

Ürün Linki

örnekleme

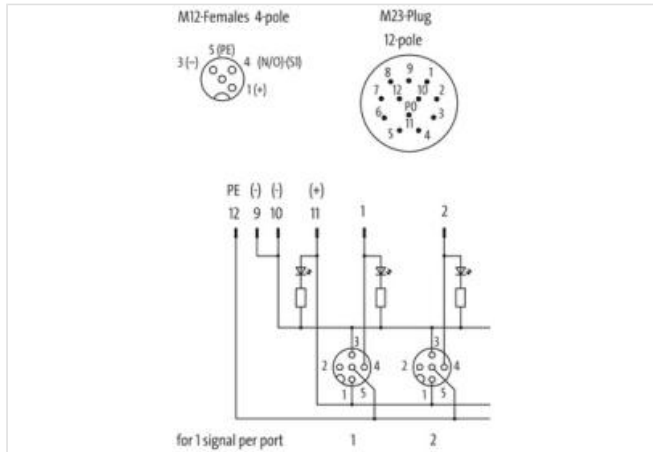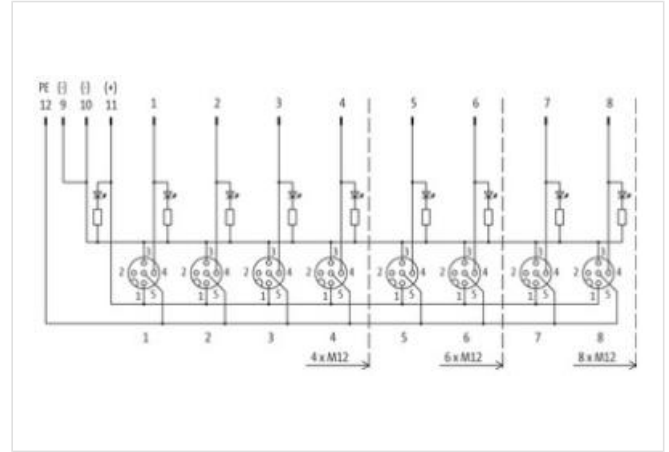

Ürün Image farklı olabilir

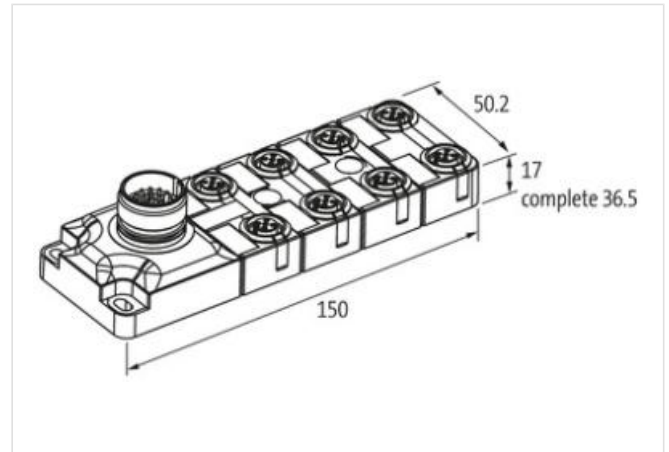

Ticari bilgiler

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219

ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
GTIN	4048879054188
Gümrük tarife no (gtip)	85369010
Paket miktarı	1
Electrical data Supply	
Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current max.	8 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65, IP67
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	75 °C
Connection type 1	
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	4
PIN 1	+
PIN 2	n.c.
PIN 3	-
PIN 4	NO S 1
PIN 5	PE