

EXACT12, 8XM12, 4 POLE

Conn.M12 12-pole

8-way

4-pole (port 3...8)

5-pole (port 1+2)



M12 plug connection, 12-pole

with LED for digital PNP-signals 24 V DC


Plastic housings with good resistance against chemicals and oils.

Ürün Linki

örnekleme

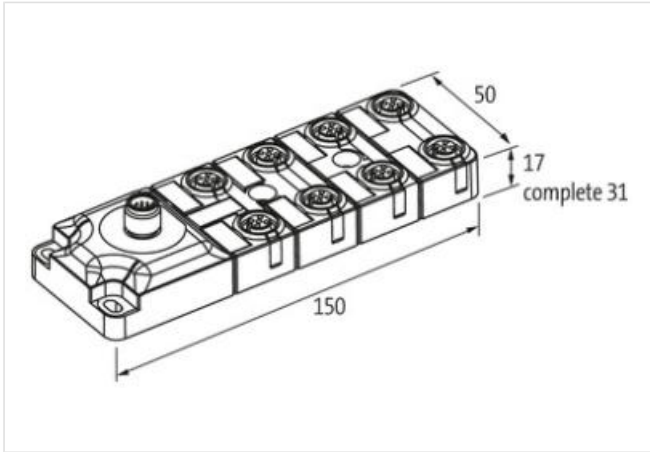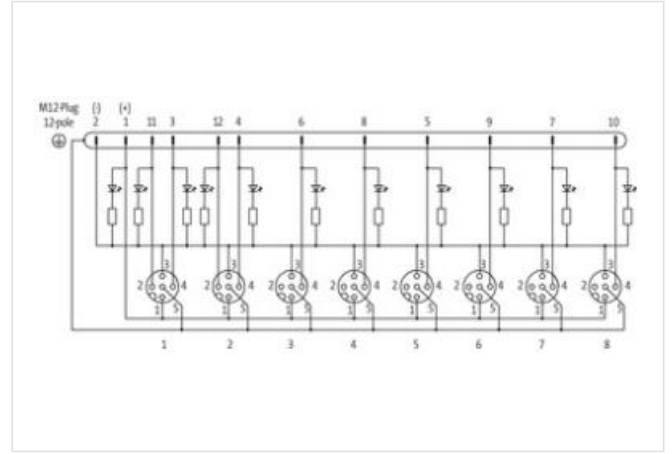

Ürün Image farklı olabilir

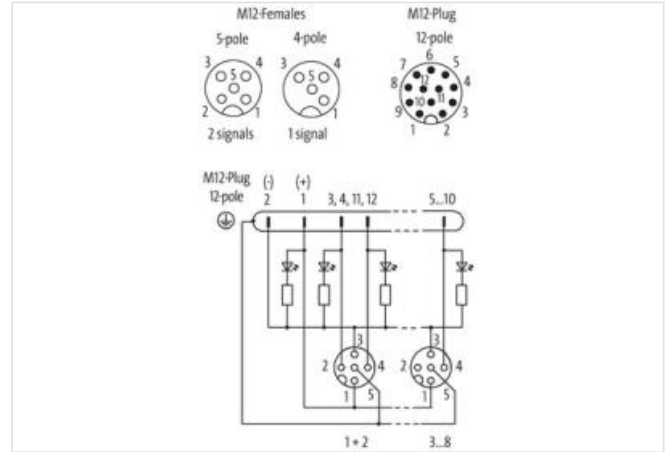

Ticari bilgiler

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219

ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
GTIN	4048879313155
Gümrük tarife no (gtip)	85369010
Paket miktarı	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	1,5 A
Total current max.	1,5 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67
-------------------------------------	------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C

Connection type 2

Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	4
PIN 1	+
PIN 2	n.c.
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	12
PIN 1	+
PIN 2	-