

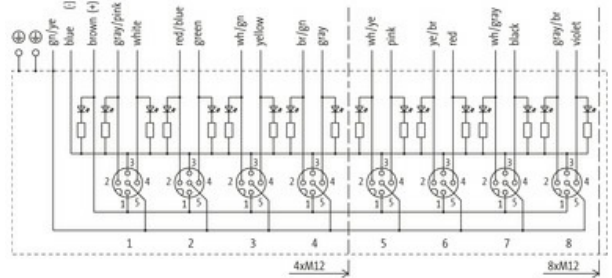
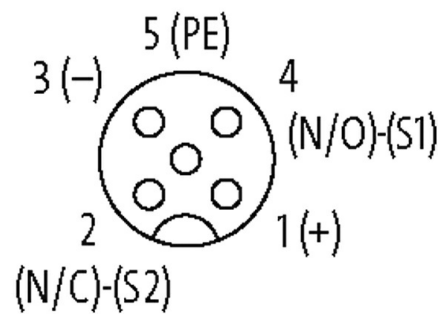
MVP XTREME 8XM12, 5-POLE, FIXED CABLE

25m PUR, 16x0.5+3x1.0, bl halogen free UL/CSA

3.0 m

Ürün Linki

örnekleme

**M12 Females 5-pole**

Ürün Image farklı olabilir

Onaylar

Approvals

Daha Fazla Bilgi

Bus technologies

Technical Data

Operating voltage

24 V DC

Bu broşürdeki bilgiler itina ile derlenmiştir.
Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalî sınırlıdır. Sürüm: 05/21

Murrelektronik GmbH | Falkenstr. 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm)
Protection	IP65, IP67, IP68
Housing	Plastic housing

General data

Temperature range	-30...+85 °C
-------------------	--------------

Cables

No./diameter of wires	16× 0.5 + 3× 1.0 mm ²
Wire isolation	TPE (grpk, wh, rd, rdbl, gn, whgn, ye, brgn, gr, whye, pk, yebr, rd, whgr, bk, grbr, vi, br, bl, gnye)
C-track properties	5 Mio.
Outer Ø	11.5 mm ±5%
Cable number	456
Approval (cable)	UL (AWM-Style 20233), CSA
Material (wire)	Cu wire, bare
Jacket Color	black
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+80 °C
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Torsion stress	0.5 Mio. ±180°/m
Material (jacket)	PUR (UL/CSA)

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)
LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)	

Ticari bilgiler

EAN	4048879315142
eClass	27143423
Gümrük tarife no (gtip)	85444290
Menşei	CZ
Paket miktarı	1.000