

MICO IP67 electronic circuit protection, 4 Channels, 2A

IN: 24 V DC OUT: 24 V DC / 2 A CL2 / Expandable

MICO67 4.2 CL2

4 x M12, A-coded NEC CL2, (2 A)

Voltage IN and transmission via M12, L-coded (16 A)

24 V/16 A



24 V/2 A

LED port diagnostic

Limitation of the 4 voltage taps to 2 A (M12, A-coded)

Ürün Linki

örnekleme

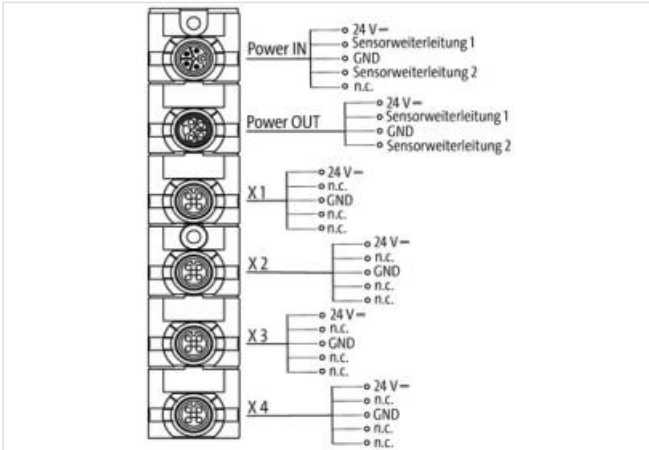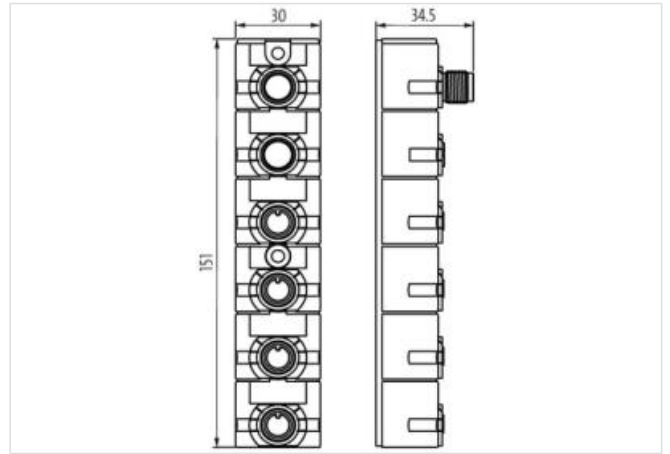

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-11.1	27371802
GTIN	4048879852272
Gümrük tarife no (gtip)	85363010

Paket miktarı 1

Device protection | Electrical

Degree of protection (EN IEC 60529) IP65, IP67

Environmental characteristics | Climatic

Operating temperature min. -25 °C

Operating temperature max. 45 °C

Storage temperature min. -25 °C

Storage temperature max. 70 °C