


MODL. VARIO 8-way rectangle coupling housing

nickel plated aluminum, nickel plated steel

Mobile housing (rectangular)
8-way**Ürün Linki**

örnekleme

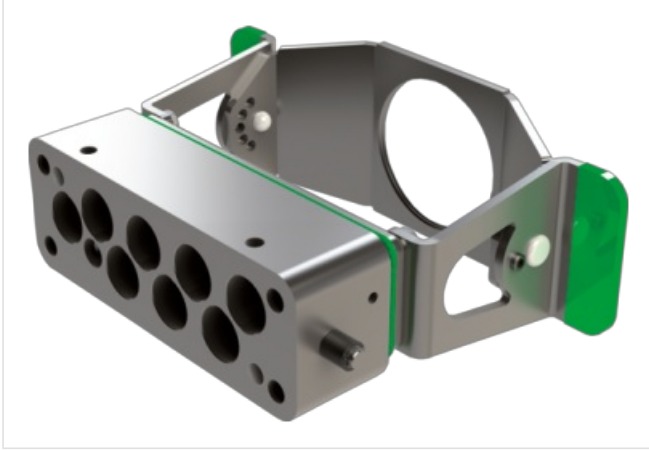

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27260702
ECLASS-6.1	27260708
ECLASS-7.0	27440312
ECLASS-8.0	27440312
ECLASS-9.0	27440312
ECLASS-10.1	27440312
ECLASS-11.1	27440312
ECLASS-12.0	27440312
ETIM-5.0	EC002641
GTIN	4048879621830
Gümrük tarife no (gtip)	85389099
Paket miktarı	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67, IP68
Degree of protection (ISO 20653:2013)	IP66K, IP69K
Additional condition protection degree	inserted, screwed

Mechanical data | Mounting data

Looking techniques	Clip locking
--------------------	--------------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	120 °C