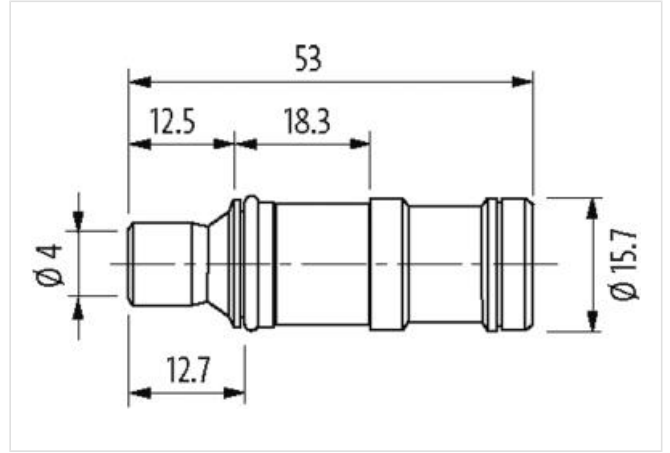


MODL. VARIO insert for fixed housing type B

4/2 shut-off, nickel plated brass

Insert - stationary housing
Brass, nickel plated
with shut-off
AD4

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27260702
ECLASS-6.1	27260708
ECLASS-7.0	27440312
ECLASS-8.0	27440312
ECLASS-9.0	27440312
ECLASS-10.1	27440312
ECLASS-11.1	27440312
ECLASS-12.0	27440312
ETIM-5.0	EC002641
GTIN	4048879573733
Gümrük tarife no (gtip)	74198090
Paket miktarı	1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67, IP68
Degree of protection (ISO 20653:2013)	IP66K, IP69K
Additional condition protection degree	inserted, screwed

Mechanical data

Barrier	with shut-off
Operating pressure min.	0 bar
Operating pressure max.	16 bar

Mechanical data | Material data

Coating housing	nickel plated
Material gasket	FPM
Material housing	Brass

Mechanical data | Mounting data

Outer diameter hose 4 mm

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 120 °C